




15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Ivory

By Bryant
Catalog # [USBB20C5IWR](#)

15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Ivory

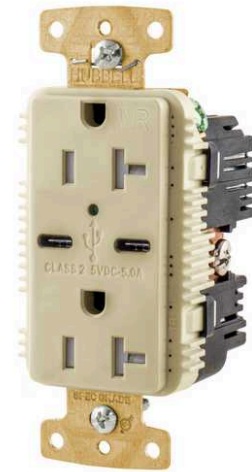

General

Color	Ivory
Number Of Poles	2
Series	USB Charger
Style	Style Line Decorator
Type	Two Type-C USB Ports

Electrical Ratings

Current / Amperage Rating	20 A
Voltage Rating Description	125 V

Conductor Related

Number Of Wires	3
-----------------	---

Certifications and Compliance

Nema Rating	5-20R
-------------	-------

Product Assets

Related Products

- [USBB20C5WR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Brown](#)
- [USBB20C5LAWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Light Almond P26I - Wallplate, 1-Gang, 1\) Decorator, Ivory](#)
- [USBB20C5BKWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Black](#)
- [USBB20C5GYWR - 15A/125V Tamper Resistant/Weather Resistant Duplex Receptacle & Type C USB Port, Gray](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRY-USBB20C5IWR-SPEC-EN | REV 7/2023