

Locking Devices
15A, 125V, 2 Pole, 3 Wire Grounding
Elastogrip® Plug



Features

- Integral weatherproofing shroud seals connection between plug and connector
- Nylon compression nut keeps water and dust from getting into the body around the cord



Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Elastogrip plug, yellow elastomer, water/dust tight	.300"-.655" (7.6-16.6)	781786378278	BRY24W47

Listings


Listed to UL 498
Fed.Spec. W-C-596
Certified to CSA C22.2 No.42

Specifications

Terminal Retainer	Clear polycarbonate
Strain Relief Nut	Nylon
Blades	Brass
Terminal Screws	Brass
Assembly Screws	Steel, zinc plated

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accommodation	#18 AWG- #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

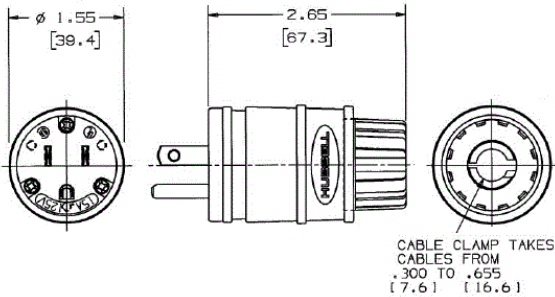

Accessories

Connector	HBL25W47
-----------	----------

Resources

Customer Use Drawing
eCatalog