

Watertight Devices  
Accessories  
Portable Outlet Box



**Features**

- Fully thermoplastic elastomer housing exceeds UL crush requirements
- Wiring room large enough to accommodate the broadest range of device requirements
- Brass inserts for maximum strength

**Ordering Information**

Description	Device Color	UPC	Catalog Number
Portable outlet box with (2) duplex plates	Yellow	781786379602	BRY3000

**Listings**



Listed to UL514C  
UL Type 3R  
Meets NEMA WD-1, WD-6 and ANSI standards

**Specifications**

Box Enclosure	Thermoplastic Elastomer
Gotcha Ring	Polypropylene
Strain Relief Nut	Nylon
Grommet	Thermoplastic Elastomer
Locknut	Steel, Zinc Plate
Threaded Inserts	Brass

**Performance**

Environmental	
Flammability	UL94 V-0
Moisture Resistance	UL Type 3R
Operating temperatures	-40°C (without impact) to +60°C continuous
UV Resistance	All exposed materials are UV stabilized
Mechanical	
Cord Accomodation	.38" - .63"

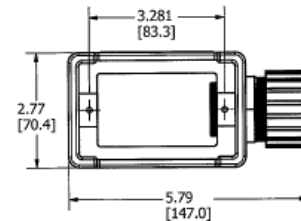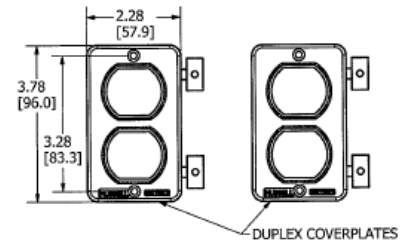

**Complementary Products**

UL Type 1 duplex outlet box cover	HBL3051
UL Type 3R duplex outlet box cover	HBL3056
UL Type 1 outlet box cover with 1.39" diameter single receptacle	HBL3052
UL Type 3R outlet box cover with 1.39" diameter single receptacle	HBL3057
UL Type 1 outlet box cover with 1.57" diameter single receptacle	HBL3055
UL Type 3R outlet box cover with 1.57" diameter single receptacle	HBL3058
UL Type 1 outlet box cover for GFCI receptacle	HBL3060
UL Type 3 outlet box cover for GFCI receptacle	HBL3061
Blank outlet box coverplate	HBL3054

Dimensions in Inches (mm)

Bryant Electric • An affiliate of Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484  
Phone (800) 323-2792 • Specifications subject to change without notice

**Online Resources**

[eCatalog](#)