

### Features

- Fully Programmable Schedules
- Neutral Wire Required
- Interchangeable Color Cover
- Compatible with "3-Way" Configuration

### Ordering Information

Description	Device Color	UPC Number	Catalog Number
Wall Switch Timer with Astronomical Features	Gray, White, Light Almond	781786197138	DTP120



### Listings


UL 917 and 244A Listed

### Specifications

Housing	Polycarbonate
Mounting Strap	Zinc Plated Steel
Dimensions (Overall)	4.125" H x 1.625" W x 1.50" D

### Performance

<b>Electrical</b>	
Operating Voltage	120V AC
Wiring	Neutral Wire Required
<b>Mechanical</b>	
Terminal Accommodations	#14 AWG min. - #12 AWG max.
<b>Environmental</b>	
Operating Location	Indoor Use Only
Operating Temperature	32°F to 104°F (0°C to 40°C) with rate of change not exceeding 20°F(11°C) per hour
<b>Controls</b>	
Operation Modes	Automatic, Countdown, Manual and Random
<b>Load Capacity</b>	
Electronic Ballast/LED	5A
Motor	1/2 hp
Resistive	15A

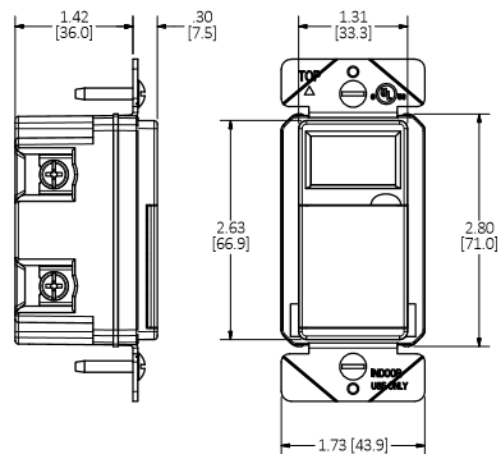

### Complementary Products

Nylon Wallplate	NP26GY, NP26LA, NP26W
SS Wallplate	SS26