


# In-wall Add-On Switch

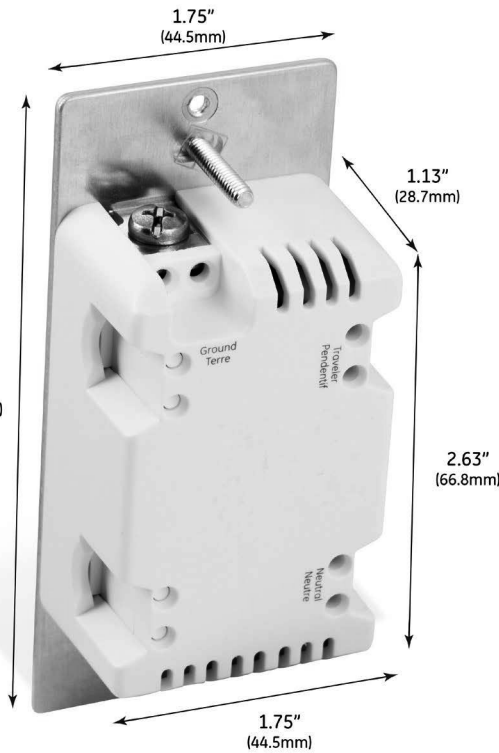

4.13"  
(104.9mm)



## Specifications

**Power:** 120/277VAC, 60Hz

**Operating Temperature:** 32-104° F (0-40° C)

**Warranty:** 5-year limited product warranty

**Switch must be mounted indoors**

## Design Features

- iDevices® model IDEVZ03DW for use in 3, 4, 5, or 6-way wiring configurations with: iDevices® models, IDEVZ01DW and IDEVZ05DW
- Requires wiring connections Neutral, Traveler and Ground
- Uses a standard decorative wall plate (wall plate not included)
- Maximum number of Add-On Switches connected to primary switch: 4
- Maximum traveler wire distance: 300ft., interconnected between 4 Add-On switches
- No more than 75ft between each switch
- Maximum traveler wire distance between primary and (1) Add-On switch: 200ft
- Not for direct control of load (Not a standalone switch)
- Requires iDevices® Smart Control for operation

## Related Products - iDevices® Z-Wave Products



**IDEVZ05DW**  
In-Wall  
Smart Dimmer



**IDEVZ01DW**  
In-Wall  
Smart Switch



**IDEVZ08W**  
Smart Tamper  
Resistant  
Receptacle

White/light almond  
paddles included



Compliances, specifications and availability are subject to change without notice.

DISTRIBUTED BY  
BRYANT ELECTRIC  
HUBBELL INCORPORATED  
(DELAWARE)  
SHELTON, CT 06484

©Hubbell | IDEVZ03DW | 2021 v1.1BRY

