


In-wall Toggle Add-On Switch

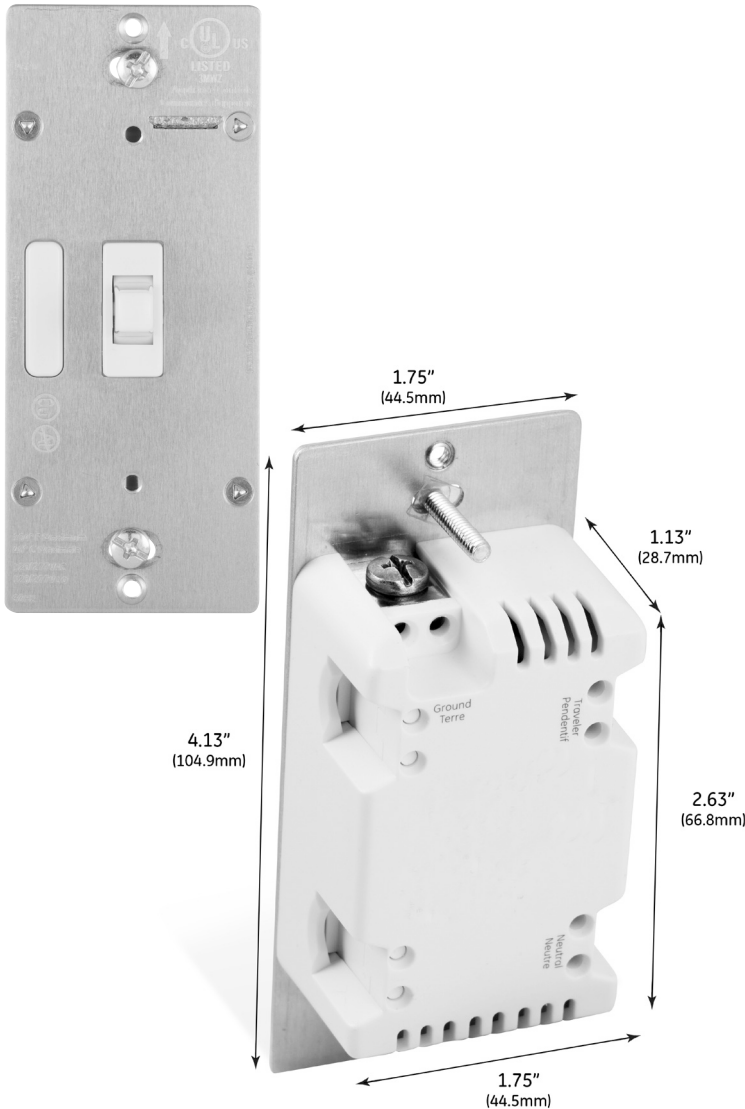

Specifications

Power: 120-277VAC, 60Hz
Operating Temperature: 32-104° F (0-40° C)
Switch must be mounted indoors

Design Features

- iDevices® model IDEVZ03TW for use in 3, 4, 5, or 6-way wiring configurations with:
iDevices® models, IDEVZ01TW and IDEVZ05TW
- Requires wiring connections Neutral, Traveler and Ground
- Uses a standard toggle wall plate (wall plate not included)
- Toggle style switch to match existing switches
- Maximum number of Add-On Switches connected to primary switch: 4
- Maximum traveler wire distance: 300ft., interconnected between 4 Add-On switches
- No more than 75ft between each switch
- Maximum traveler wire distance between primary and (1) Add-On switch: 200ft
- Not for direct control of load (Not a standalone switch)

Certifications & Compliances



Compliances, specifications and availability are subject to change without notice.

DISTRIBUTED BY
 BRYANT ELECTRIC
 HUBBELL INCORPORATED (DELAWARE)
 SHELTON, CT 06484

©Hubbell | IDEVZ07W | 2022 v1.1BRY
 Questions? Contact our U.S.-based

Consumer Care at
 1-800-323-2792. www.bryant-electric.com

Related Products - iDevices® Z-Wave Products



IDEVZ01TW
 In-Wall
 Smart Switch



IDEVZ05TW
 In-Wall
 Smart Dimmer



IDEVZ08W
 Smart Tamper
 Resistant
 Receptacle

