

TradeSelect®
Single Pole, 15A 120V AC
Switches and Lighting Controls
2 Single Pole Toggles



Features

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears

Ordering Information

Description	UPC	Catalog Number
TradeSelect, Combination, Grounding, Push and Side Wire, 15A 120V AC, 2 Single Pole Toggles, White	883778109799	RC101W

Listings

CSA Certified
 UL Listed E3896

Specifications


Color	White nylon
Contact Configuration	Two Position
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Switch Combo Devices
Mounting Hardware	Mounting Screws
Number Of Poles	2- Single Pole

Performance

Operating Cycles	30,000 Minimum
Operating Temperature	Max Continuous- 60 Degrees C, Minimum- -20 Without Impact
Performance	Environmental - Operating temperature - -20°C to 60°C

Electrical

Amperage Rating	15 A
Connectivity	Side Wired
Contact Rating	15A
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	120 VAC
Voltage Rating Description	120 VAC
Wattage	1800

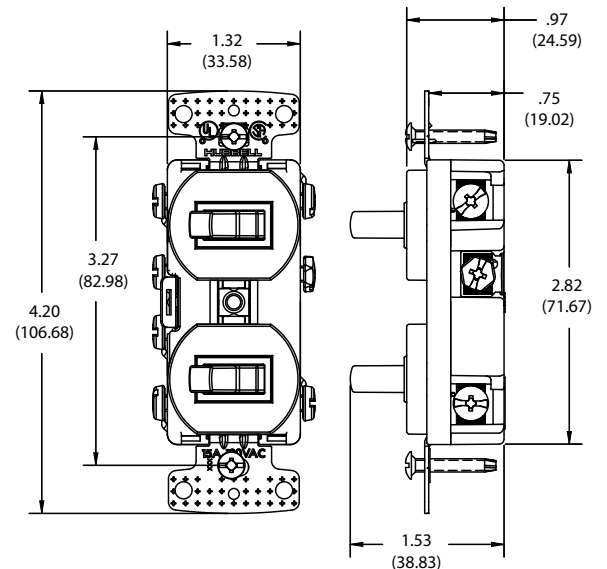

Links

- [Customer Drawings](#)
- [Installation Instructions](#)
- [Media](#)

Dimensions in Inches (mm)

Bryant Electric • An affiliate of Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484
 Phone (800) 323-2792 • Specifications subject to change without notice