

TradeSelect®
20A 125V AC; 2 Pole, 3 Wire Grounding
Straight Blade Receptacle, Clock Hanger



Features

- Tamper-Resistant Clock Hanger/Recessed Receptacle
- Multiple drive Slot/Phillips/Robertson head screws
- UL Listed



Ordering Information

Description	UPC	Catalog Number
TradeSelect, Straight Blade, Single Receptacle, Clock Hanger, Tamper Resistant, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, White Plate	883778302220	RR201CHWTR

Listings

UL Listed




Specifications

Color	Natural (white) nylon
Material	Thermoplastic
Material - Mounting Hardware	Screw Mounting

Performance

Amperage Rating	20 A
Connectivity	Back and Side Wired Screw Terminals
Current / Amperage Rating	15 A
Current Rating	20 A
Phase	Single Phase
Voltage Rating	125 V
Wattage	2500
Wire Size	#14 AWG to #12 AWG

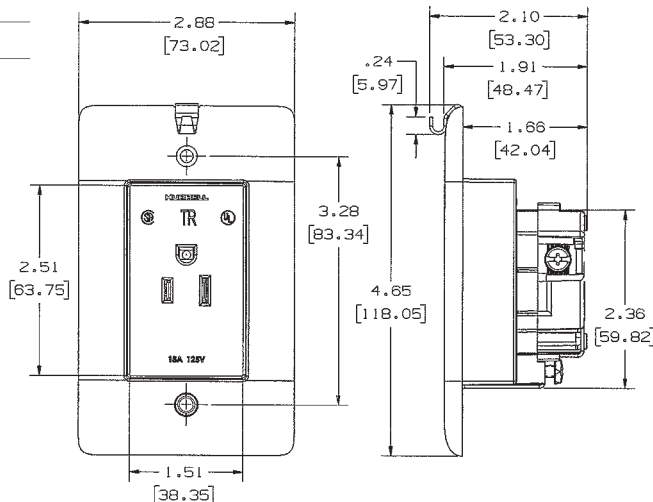

Links

- [Customer Drawings](#)
- [Installation Instructions](#)
- [Media](#)

Dimensions in Inches (mm)

Bryant Electric • An affiliate of Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484
 Phone (800) 323-2792 • Specifications subject to change without notice