 


TradeSelect® Residential Grade 50A 125/250V, 3-Pole 4-Wire Grounding Surface Mount Receptacle

BRYANT

Features

- Flush Mount for 1- or 2-Gang Box
- Residential Range and Dryer Receptacle



Ordering Information

Description	Color	UPC	Catalog Number
TradeSelect Flush Mount Receptacle for 1- or 2-Gang Box 50A 125/250V 3 Pole, 4 Wire with Ground	Black	883778100833	RR450

Listings



UL Listed

Specifications

Color	Black
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Series	Heavy Duty
Type	Single Receptacle

Electrical

Amperage Rating	50 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	50 A
Current Rating	50 A
Phase	Single Phase
Voltage Rating	125/250 V
Voltage Rating Description	125/250 V
Wattage	12500
Number Of Wires	4-Wire
Wire Size	#6 AWG

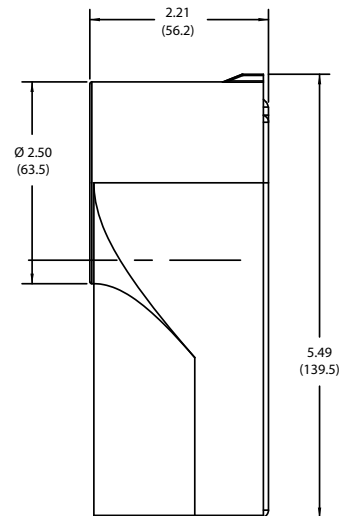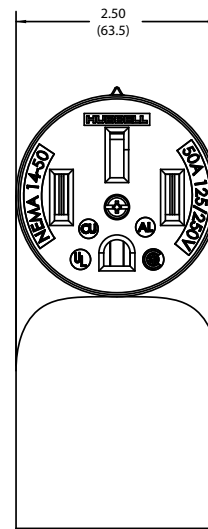

Links

- [Customer Drawings](#)
- [Installation Instructions](#)
- [Media](#)

Dimensions in Inches (mm)

Bryant Electric • An affiliate of Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484
Phone (800) 323-2792 • Specifications subject to change without notice