

# Straight Blade Devices

## 15A, 125V, 2 Pole, 3 Wire Grounding

### USB Charger Duplex Receptacle

# BRYANT®

#### Features

- High Power 3.1 Amp, 5 Volt USB Output
- Two Type A USB Ports
- Tamper Resistant Grade Duplex Compatible
- USB Ports Rated 10,000 Cycles

#### Ordering Information

Description	Color	UPC Number	Catalog Number
Tamper Resistant 15A/125V Duplex, 3.1 Amp, 5 Volts USB Ports	Light Almond	781786917095	USBB15ALA

#### Listings

cULus Listed to UL498, UL1310

#### Specifications

Mounting Strap	.040" Zinc Plated Steel
Face	Reinforce Thermoplastic
Base	Reinforce Thermoplastic
USB Port	Stainless Steel
Contacts	Plated Steel
Clamp	Plated Steel
Terminal Screws	Plated Steel
Mounting Screws	Zinc Plated Steel

#### Performance

##### Electrical

Current Interrupting Certified for current interrupting at full rated current



Dielectric Voltage Withstands 1,500 V minimum  
Complies with USB BC1.2 Battery Charging and 3.0 Power Delivery Specifications

##### Mechanical

Product Identification Ratings are a permanent part of the device  
Terminal Accommodation #14-#10 AWG copper stranded or solid conductor only  
Terminal Identification Terminals identified in accordance with UL 498 and CSA  
USB Ports Stainless steel rated for 10,000 plug insertions and removal

##### Environmental

Flammability UL 94V-2  
Operating Temperature Maximum continuous 75°C, minimum -40°C (w/o impact)

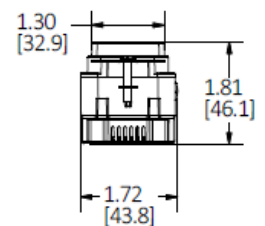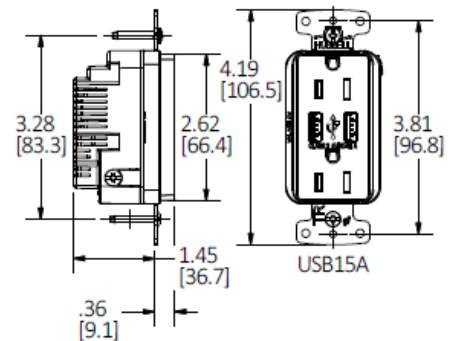

Dimensions in Inches (mm)

Bryant Electric • An affiliate of Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 323-2792 • Specifications subject to change without notice