


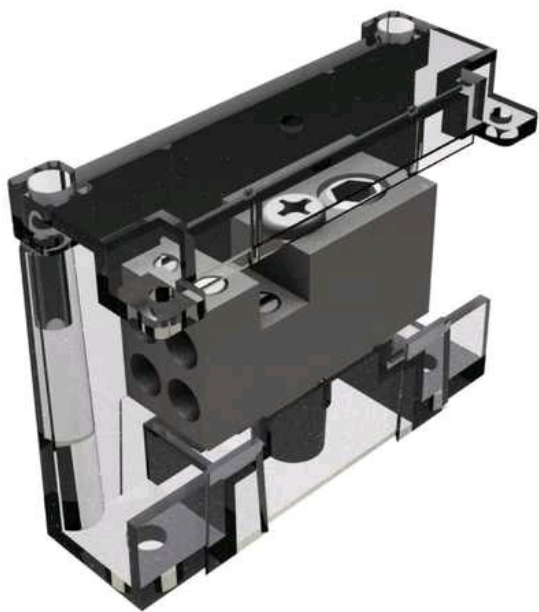

BDB222/02

by Burndy
Catalog ID: BDB222/02

POWER DISTRIBUTION BLOCKS.

Product Details

General

Insulation	Y
Insulation Type	Thermoplastic
Material	Aluminum
Number Of Poles	2
Plated	Y
Plating Type	Tin
Temperature Rating	194
Trade Name	VERSIPOLE™
UPC	781810115770
UPC 12 Digit	7818101157700

Electrical Ratings

Amperage Rating	350 A
Rating - Minimum Voltage	600

Conductor Related

Conductor - AL Str Run	8 AWG;6 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG
Conductor - AL Str Run Range	8 AWG-2/0 AWG
Conductor - AL Str Tap	8 AWG;6 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG
Conductor - AL Str Tap Range	8 AWG-2/0 AWG
Conductor - Copper Str Run	14 AWG;12 AWG;10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Run Range	14 AWG-2/0 AWG
Conductor - Copper Str Tap	14 AWG;12 AWG;10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG
Conductor - Copper Str Tap Range	14 AWG-2/0 AWG

Conductor Type	• AL C Str-Run • CU C Str-Run • AL C Str-Tap • CU C Str-Tap
----------------	---

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	Yes
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Minimum Pack Quantity	1
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)