


BGM10160

by Burndy
Catalog ID: BGM10160

GRIDMAX Copper Ground Mesh 10' X 160' 12" Centers #8 AWG.

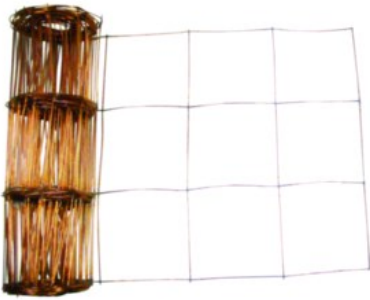

Product Details

General

Trade Name	GRIDMAX®
UPC	781810511091
UPC 12 Digit	7818105110911

Dimensions

Dimension - Height inch	130 in
Dimension - Width inch	10 in

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	2
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)