


## BGM1080

by Burndy  
Catalog ID: BGM1080

GRIDMAX Copper Ground Mesh 10' X 80' 12" Centers #8 AWG.

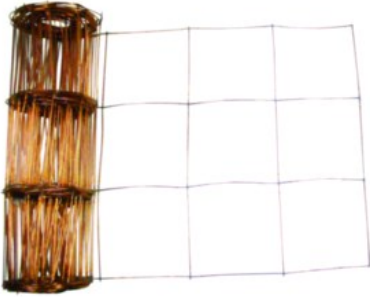

### Product Details

#### General

Trade Name	GRIDMAX®
UPC	781810511114
UPC 12 Digit	7818105111144

#### Dimensions

Dimension - Height inch	180 in
Dimension - Width inch	10 in

#### Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

#### Logistics

Minimum Pack Quantity	1
-----------------------	---

**For further technical assistance, please contact us**

**BURNDY Headquarters**  
47 East Industrial Park Drive  
Manchester, New Hampshire 03109

**Customer Service Hours:**  
8 AM - 8 PM Eastern Monday-Friday  
Emergency Service 24-hours/365 Days  
Phone: 1-800-346-4175  
1-603-647-5299 (International)