


## CT18125C

by Burndy  
Catalog ID: CT18125C

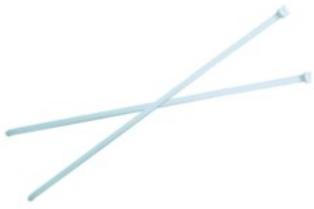

Nylon cable ties, Tensile strength-18 Lbs, Color- Natural, 6.18" L, 0.09" W, 1.50" Bundle Dia.

- Standard Cable Tie

## Product Details

### General

Color	Natural
Material	Nylon 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	18
Tool Type	Mini
Trade Name	UNIRAP™
UPC	781810331446

### Dimensions

Dimension - Bundle Diameter Max inch	1.50 in
Dimension - L Length Overall mm	157 mm
Dimension - Length Overall inch	6.18 in
Dimension - Width inch	0.09 in
Dimension - Width mm	2 mm

### Certifications and Compliance

Certification - 94VO Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

### Logistics

Carton Quantity	1000 EA
Minimum Pack Quantity	100
Packaging Type	Bag

**BURNDY Headquarters**  
47 East Industrial Park Drive  
Manchester, New Hampshire 03109

**Customer Service Hours:**  
8 AM - 8 PM Eastern Monday-Friday  
Emergency Service 24-hours/365 Days  
Phone: 1-800-346-4175  
1-603-647-5299 (International)