


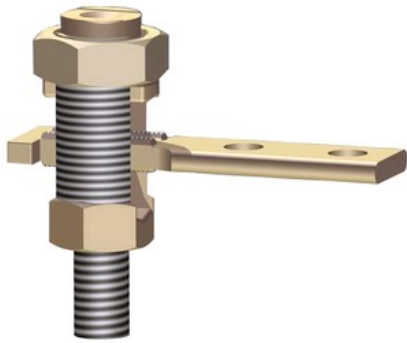

SB252TC14

by Burndy
Catalog ID: SB252TC14

Prop 65 Notice

2 AWG - 1/0 AWG CU SOL/STR, WIRE STRIP LENGTH: 1 - 1/8".

Can be used for splicing and tap connections, No special tooling required.

Product Details

General

Application	Power or Grounding and Bonding Applications
Material	Copper Alloy, Tin Plated
Plated	N
Plating Type	Unplated
Stud Installation Torque inch pounds	480 in-lbs
Sub Brand	HANDYBUG
Trade Name	SUPERBUG
Type	HandyBug
UPC	781810677421
UPC 12 Digit	7818106774211

Dimensions

Dimension - L Length Overall mm	0 mm
Dimension - Thread Size	-
Dimension - Width mm	0 mm

Conductor Related

Conductor Range	#2 AWG to #1/0 AWG
-----------------	--------------------

Certifications and Compliance

Certification - ETL	No
Certification - cULus	Y
Standards - RoHS Compliance Status	EX

Logistics

Minimum Pack Quantity	1
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)