


YCS26RL

by Burndy
Catalog ID: YCS26RL

Prop 65 Notice

HYSPLICE AL sleeve with staked cable stop, designed to withstand jumper loop tensile and vibration stresses, Conductor: 1/0 (ACSR, 6201, 5005, AAC)

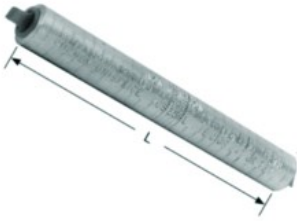

Product Details

General

| | |
|---------------------------|---------------|
| Connector Type | Splice |
| Die Index | 659 |
| Material | Aluminum |
| Plated | N |
| Plating Type | Unplated |
| Prefilled Oxide Inhibitor | Y |
| Trade Name | UNISPLICE™ |
| UPC | 781810015018 |
| UPC 12 Digit | 7818100150188 |

Dimensions

| | |
|-----------------------------------|---------|
| Dimension - B Length inch | 2.7 in |
| Dimension - L Length Overall mm | 141 mm |
| Dimension - Length Overall inch | 5.56 in |
| Dimension - Outside Diameter inch | 0.83 in |

Conductor Related

| | |
|----------------------------------|---------------------|
| Conductor - AAAC 5005 Size | 2/0 (7) AWG |
| Conductor - AAAC 5005 Size Range | 2/0 (7) AWG |
| Conductor - AAAC 6201 Size | 2/0 (7) AWG |
| Conductor - AAAC 6201 Size Range | 2/0 (7) AWG |
| Conductor - ACSR Str Size | 2/0 (6/1) Quail AWG |
| Conductor - ACSR Str Size Range | 2/0 (6/1) Quail AWG |
| Conductor - AL Str Size | 2/0 (7) AWG |
| Conductor - AL Str Size Range | 2/0 (7) AWG |

Certifications and Compliance

| | |
|------------------------------------|----|
| Certification - CSA Approved | No |
| Certification - ETL | No |
| Certification - UL Recognized | No |
| Certification - cULus | No |
| Standards - RoHS Compliance Status | CM |

| | |
|-----------|----|
| UL Listed | No |
|-----------|----|

Logistics

| | |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
|-----------------------|---|

For further technical assistance, please contact us

BURNDY Headquarters

47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:

8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)