


YP2C2

by Burndy
Catalog ID: YP2C2

Prop 65 Notice

Figure 6 - shaped, wide range-taking CU compression tap connector for primary service taps and secondary service drops, Width: .75 IN.

Features: Compression Tap Connector For Primary Service Taps And Secondary Service Drops, Connector Can Be Gripped In Tool And Slipped Over The Line For Easy Installation, Conductor Type: Run And Tap: Copper, Conductor Size (run - Range): 6 AWG Solid - 2 AWG Stranded, Conductor Size (tap Range): 6 AWG Solid - 2 AWG Stranded, Shape: 6, Die Index: O Element A, Tools, Die Set Catalog Number, And (number Of Crimps): Y35, Y750, Y45, Y46 Tool, U-O Die, (1)

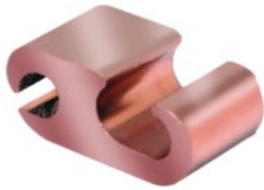

Product Details

General

Application	For Extra Wide Range Of Copper And Primary Service Taps And Secondary Service Drops
Connector Type	Tap
Die Index	O
Material	Copper
Plated	Y
Plating Type	Unplated
Sub Brand	CRIMPIT
Trade Name	CRIMPIT™
Type	YP-C
UPC	781810117903
UPC 12 Digit	7818101179033

Dimensions

Dimension - Height inch	1.45 in
Dimension - L Length Overall mm	19 mm
Dimension - Length Overall inch	0.75 in

Conductor Related

Conductor - Copper Solid Run	6 AWG
Conductor - Copper Solid Tap	6 AWG
Conductor - Copper Str Run	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Run Range	6 AWG-2 AWG
Conductor - Copper Str Tap	6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Str Tap Range	6 AWG-2 AWG

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No

Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Minimum Pack Quantity	1
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters

47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:

8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)