


# CFPX46WOH

by CMC

Catalog ID: CFPX46WOH

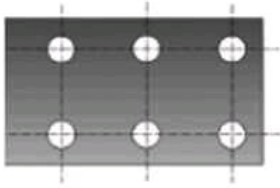

Aluminum flat pad extensions, without hardware, 600 V

- 16 Large or 10 ¼ Medium Scale
- Choice of Acrylic, Polycarbonate Lensing
- IES Distributions
- Clear or Diffused Lensing
- Integral surge and thermal protection

## Product Details

### General

Color	<ul style="list-style-type: none"> <li>• Black Matte Textured</li> <li>• Black Gloss Smooth</li> <li>• Dark Bronze Matte Textured</li> <li>• Dark Bronze Gloss Smooth</li> <li>• Graphite Matte Textured</li> <li>• Light Grey Gloss Smooth</li> <li>• Platinum Silver Smooth</li> <li>• White Matte Textured</li> <li>• White Gloss Smooth</li> <li>• Verde Green Textured</li> </ul>
Controls - Applications	<ul style="list-style-type: none"> <li>• On/Off</li> <li>• Scheduled Dimming</li> <li>• Dusk to Dawn Operation</li> </ul>
Controls - Integral Sensors (Non-Networked)	<ul style="list-style-type: none"> <li>• Photocell- Button (optional)</li> <li>• Profile Dimming</li> </ul>
Dimming Protocol	0-10V
Dimming Range	Dims to 10% Brightness

Lumen Range	<ul style="list-style-type: none"> <li>• 1-2,500 lm</li> <li>• 2,501-5,000 lm</li> <li>• 5,001-10,000 lm</li> <li>• 10,001-30,000 lm</li> </ul>
Mounting Type	<ul style="list-style-type: none"> <li>• Wall (surface)</li> <li>• Arm</li> <li>• Post Top</li> <li>• Pendant (3/4" threaded coupling)</li> </ul>
Sensor Type	Photoresistor
UPC	192663107308

## Dimensions

Dimension - Hole Size inch	0.56 in
Height	3 in
Length	8.5 in
Thickness	0.5 in

## Electrical Ratings

Frequency Rating	50/60 Hz
------------------	----------

## Certifications and Compliance

DarkSky	No
Industry Standard(s)	cUL