




Horizontal Pin Standoff Bracket, 18"

By Chance

Catalog # [1SBH18H2](#)

18" Heavy Duty Fiberglass Single-Phase Horizontal Pin Standoff Bracket with 1" Nylon Threads

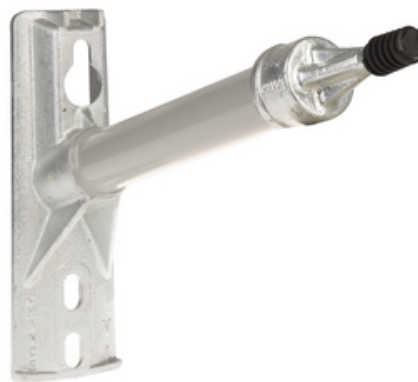

*Representative Image

Features

- Pin Type Insulator
- 1" Nylon Threads

General

Catalog Number	1SBH18H2
Description - End Fitting	Horizontal Pin
Material - Threads	1" Nylon Threads
Strength Rating - Minimum Ultimate, Longitudinal (L)	1400 lb
Strength Rating - Minimum Ultimate, Transverse (T)	1500 lb
Strength Rating - Minimum Ultimate, Vertical (V)	2300 lb

Dimensions

Diameter - Rod / Tube	2 in
Distance From Pole	18 in
Length	18 in
Mounting Bolt Spacing	8 in
	10 in
Weight	8.4 lb

Logistics

Standard Package	1
------------------	---

Product Assets

[Catalog Page - CHANCE® Fiberglass Construction Products](#)

[Sales Drawings - SA1SBHXXHX](#)