




Horizontal Pin Standoff Bracket, 14"

By Chance
Catalog # [1SBM14H4](#)

14" Medium Duty Fiberglass Single-Phase Horizontal Pin Standoff Bracket with 1.375" Lead Threads

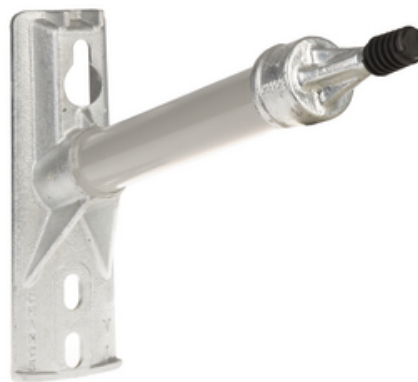

*Representative Image

Features

- Pin Type Insulator
- 1.375" Lead Threads

General

Catalog Number	1SBM14H4
Description - End Fitting	Horizontal Pin
Material - Threads	1.375" Lead Threads
Strength Rating - Minimum Ultimate, Longitudinal (L)	1600 lb
Strength Rating - Minimum Ultimate, Transverse (T)	1500 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1600 lb
UPC	096359067580

Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	14 in
Length	14 in
Mounting Bolt Spacing	6 in
	8 in
Weight	5.5 lb

Logistics

Pallet Quantity	144
Standard Package	6

Product Assets

[Catalog Page - CHANCE® Fiberglass Construction Products](#)