




Horizontal Pin Standoff Bracket, 16"

By Chance
Catalog # [1SBM16H4](#)

16" Medium Duty Fiberglass Single-Phase Horizontal Pin Standoff Bracket with 1.375" Lead Threads

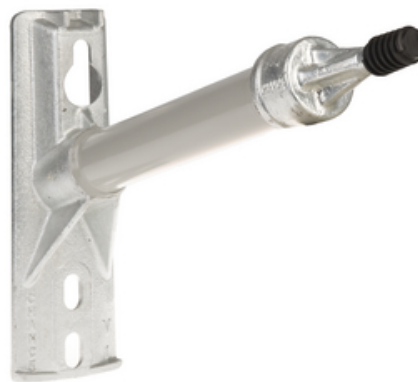

*Representative Image

Features

- Pin Type Insulator
- 1.375" Lead Threads

General

Catalog Number	1SBM16H4
Description - End Fitting	Horizontal Pin
Material - Threads	1.375" Lead Threads
Strength Rating - Minimum Ultimate, Longitudinal (L)	1350 lb
Strength Rating - Minimum Ultimate, Transverse (T)	1500 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1400 lb
UPC	096359067689

Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	16 in
Length	16 in
Mounting Bolt Spacing	6 in
	8 in
Weight	5.7 lb

Logistics

Carton Quantity	6
Pallet Quantity	120
Standard Package	1

Product Assets

[Catalog Page - CHANCE® Fiberglass Construction Products](#)