




0° 1-Position Cutout / Arrester Standoff Bracket w/ Hardware, 18"

By Chance
Catalog # [1SBM18SGLB](#)

18" Medium Duty Fiberglass 0° 1-Position Cutout / Arrester Standoff Bracket w/ Hardware

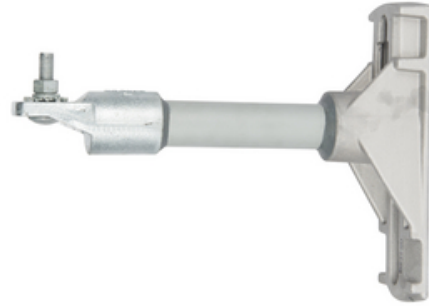

*Representative Image

Features

Not recommended for use with TripSaver® Reclosers

General

Catalog Number	1SBM18SGLB
Description - End Fitting	1 Position Apparatus Mount
Strength Rating - Minimum Ultimate, Longitudinal (L)	700 lb
Strength Rating - Minimum Ultimate, Transverse (T)	5,000 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1,500 lb
UPC	096359464532

Dimensions

Diameter - Rod / Tube	1.5 in
Dimensions	18.00 in x 1.86 in x 1.43 in
Distance From Pole	18 in
Height	1.43 in
Length	18 in
Mounting Bolt Spacing	6 in
	8 in
Weight	5.78 lb
Width	1.86 in

Electrical Ratings

Phase	1-Phase
-------	---------

Logistics

Carton Quantity	7
Pallet Quantity	168
Standard Package	1

Product Assets

[Catalog Page - CHANCE® Fiberglass Construction Products](#)
[Catalogs - CHANCE® Fiberglass Construction Products](#)
[Sales Drawings - 1 \(2\) Position \(0°\) Single-Phase](#)



A Hubbell brand