




## Horizontal Pin Standoff Bracket, 24"

By Chance  
Catalog # [1SBM24H2](#)

24" Medium Duty Fiberglass Single-Phase Horizontal Pin Standoff Bracket with 1" Nylon Threads

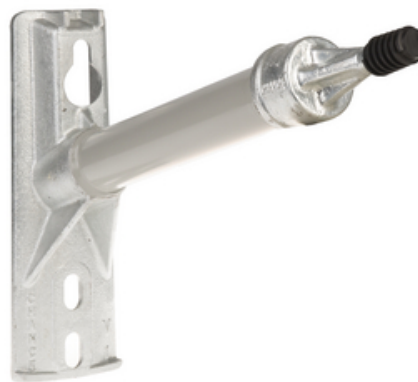

\*Representative Image

### Features

- Pin Type Insulator
- 1" Nylon Threads

### General

Catalog Number	1SBM24H2
Description - End Fitting	Horizontal Pin
Material - Threads	1" Nylon Threads
Strength Rating - Minimum Ultimate, Longitudinal (L)	900 lb
Strength Rating - Minimum Ultimate, Transverse (T)	1500 lb
Strength Rating - Minimum Ultimate, Vertical (V)	1050 lb

### Dimensions

Diameter - Rod / Tube	1.5 in
Distance From Pole	24 in
Length	24 in
Mounting Bolt Spacing	6 in
	8 in
Weight	6.7 lb

### Logistics

Standard Package	1
------------------	---

### Product Assets

[Catalog Page - CHANCE® Fiberglass Construction Products](#)