


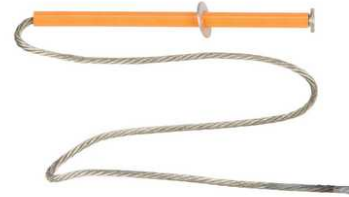

25 A, Type MS Fuseinks, 26" Length, Removable Head

By CHANCE Utility
Catalog # [M25MSA](#)

25 amp, Type MS Cutout fuselink with a 26" (660.4mm) pigtail and a removable buttonhead.



Features

- Comparable to Cooper/Kearney Type KS fuse links
- Compliant with ANSI/IEEE C37.42 - 2016 mechanical interchangeability requirements
- Compatible with universal style expulsion fuse holders
- Dual element design
- Individually packed for all weather protection
- Type and Current Rating on packaging and fuse for easy identification

General

Fuse Head Style	Removable
Fuselink Type	Type MS
Required Cutout Fuseholder	100 Amp (Do not use in a 200 amp fuseholder.)
Type	Fuselinks
UPC	096359044895

Dimensions

Length - Fuselink	26" (660.4mm)
-------------------	---------------

Electrical Ratings

Amperage Rating	25 A
-----------------	------

Logistics

Carton Quantity	200
Standard Package	10

Product Assets

[Catalogs - Fuse Links \(10B\)](#)
[Excel Files - Hubbell Time Current Characteristic Curve - Total Clearing Type MS](#)
[Excel Files - Hubbell Time Current Characteristic Curve - Minimum Melt Type MS](#)
[Literature - Switching Line Card_FAQ_2019](#)
[Sales Drawings - Fuse Links, Type MSA Removable HD \(PSSAMSAFUSELINK\)](#)
[Technical Solutions - CH-M25MSA-SPEC-EN](#)
[Test Documents - MS Min Melt](#)
[Test Documents - MS Total Clear](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
CH-M25MSA-SPEC-EN | REV 1/2024