


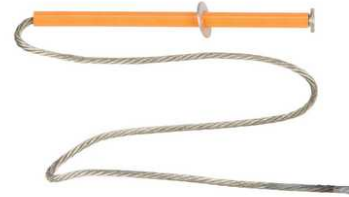

3.5 A, Type Slo-Fast Fuselinks, 23" Length, Solid Head

By CHANCE Utility
Catalog # [M3D5SF23](#)

3.5 amp, Type SloFast Cutout fuselink with a 23" (584.2mm) pigtail.



Features

- Comparable to Cooper/Kearney Type X fuse links
- Compliant with ANSI/IEEE C37.42 - 2016 mechanical interchangeability requirements
- Compatible with universal style expulsion fuse holders
- Dual element design specific for transformer protection
- Slow portion of time current characteristic curve closely matches transformers safe loading curve
- Individually packed for all weather protection
- Type and Current Rating on packaging and fuse for easy identification

General

Fuse Head Style	Solid
Fuselink Type	Type SloFast
Required Cutout Fuseholder	100 Amp (Do not use in a 200 amp fuseholder.)
Type	Fuselinks
UPC	096359045175

Dimensions

Length - Fuselink	23" (584.2mm)
Weight	0.088 lb

Electrical Ratings

Amperage Rating	3.5 A
-----------------	-------

Logistics

Pallet Quantity	4800
Standard Package	10

Product Assets

[Catalogs - Fuse Links \(10B\)](#)
[Excel Files - Hubbell Time Current Characteristic Curve - Total Clearing Type SloFast](#)
[Excel Files - Hubbell Time Current Characteristic Curve - Minimum Melt Type SloFast](#)
[Installation Manuals - Instructions for CHANCE Type M3 Distribution Switch \(P807-0198\)](#)
[Installation Manuals - Type M3C Single Insulator Disconnect Switch for Distribution Switching \(PSP8070357\)](#)
[Literature - 38KV 200 KV BIL M3 Disconnenct \(SF11038E\)](#)
[Literature - SA-M3D_C](#)
[Literature - Switching Line Card_FAQ_2019](#)
[Sales Drawings - Fuse Links, Type SF Solid & Removable HD \(PSSASFFUSELINK\)](#)
[Technical Solutions - CH-M3D5SF23-SPEC-EN](#)
[Test Documents - SloFast Min Melt](#)
[Test Documents - SloFast Total Clear](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
CH-M3D5SF23-SPEC-EN | REV 1/2024