



## Yellow-Jacket Copper Grounding Cable, #2

By CHANCE Utility  
Catalog # [S6116](#)

Copper Grounding Cable is extra-flexible for handling ease yet strong and tough for long wear. Jacketing is smooth, abrasion, weather and oilresistant in accordance with applicable ASTM Specifications, marked with AWG size approximately every 4 feet. Jackets are T-prene rubber compound with -20°F recommended low temperature. Extra-flexible cables, because of their extra-fine strands, require termination ferrules when used with grounds.

### Features

- #2 yellow-jacket copper grounding cable
- To specify cable length, please add a "P" and the length of cable in feet needed to the end of the catalog number.

### General


UPC 096359471073

### Dimensions

Weight 0.353 lb

### Electrical Ratings

Current Rating	200 A
Fault Current - 15 Cycles	14000 A
Fault Current - 30 Cycles	10000 A

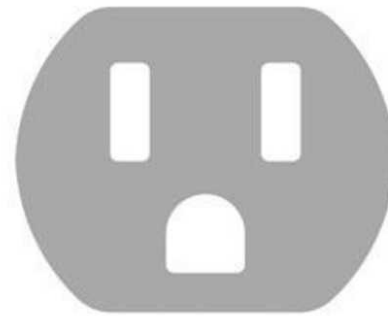

**Oh No!**  
IMAGE COMING SOON

### Conductor Related

Conductor Size	#2 AWG
Diameter - Cable Outside	0.55 In
Diameter - Conductor	.32 in
Nema Color	Yellow
Strands	665

### Product Assets

[Video - CHANCE Temporary Protective Grounding \(VI09071E0620\)](#)

[Video - CHANCE Temporary Protective Grounding \(VI09072SP0720\)](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
CH-S6116-SPEC-EN | REV 8/2023