




Jumper Set for Hotstick Applications - 15kV, 12 ft 1/0 Cable

By CHANCE Utility
Catalog # [T6010283](#)

15kV, 12' of 1/0 cable, insulated jumper for hotstick applications, main line range of 0.162" to 1.5"

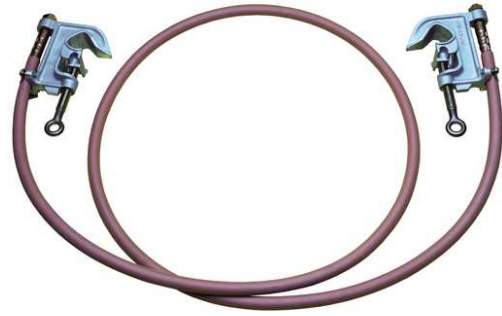

*Representative Image

Features

- Meets ASTM F2321 Standard Specification
- Two C-type grounding clamps (C6001743) and two threaded copper ferrules
- Main Line Range: #6 solid copper (0.162") through 1590kcmil ACSR (1.50")
- 15kV EPR-insulated jumper cable
- Other clamps and cable combinations available upon request

General

EU RoHS Indicator	No
Style	Hotstick Applied
UPC	096359061861

Dimensions

Length	12 ft
Weight	14.7 lb

Electrical Ratings

Amperage Rating	260
Current Rating	260 A
Voltage - Maximum	15 kV
Voltage Rating	15 kV

Conductor Related

Conductor Diameter (Main) - Maximum	1.5 in
Conductor Diameter (Main) - Minimum	0.162 in
Conductor Size	1/0 AWG

Product Assets

[Catalogs - Jumpers & Load Pickup Tools \(2300\)](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
CH-T6010283-SPEC-EN | REV 8/2023