




## Jumper Set for Hotstick Applications - 15kV, 15' 2/0 Cable

By CHANCE Utility  
Catalog # [T6010286](#)

15kV, 15' of 2/0 cable, insulated jumper for hotstick applications, main line range of 0.162" to 1.5"

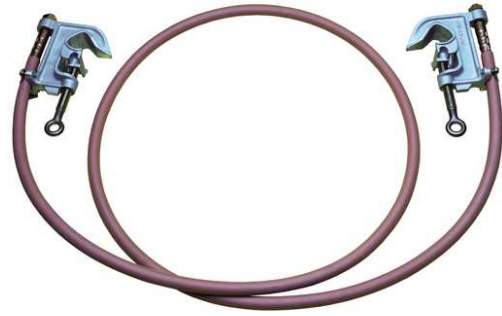

\*Representative Image

### Features

- Meets ASTM F2321 Standard Specification
- Two C-type grounding clamps (C6001743) and two threaded copper ferrules
- Main Line Range: #6 solid copper (0.162") through 1590kcmil ACSR (1.50")
- 15kV EPR-insulated jumper cable
- Other clamps and cable combinations available upon request

### General

EU RoHS Indicator	No
Style	Hotstick Applied
UPC	096359061892

### Dimensions

Length	15 ft
Weight	5.88 lb

### Electrical Ratings

Amperage Rating	300
Current Rating	300 A
Voltage - Maximum	15 kV
Voltage Rating	15 kV

### Conductor Related

Conductor Diameter (Main) - Maximum	1.5 in
Conductor Diameter (Main) - Minimum	0.162 in
Conductor Size	2/0 AWG

### Product Assets

[Catalogs - Jumpers & Load Pickup Tools \(2300\)](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
CH-T6010286-SPEC-EN | REV 8/2023