

EOL Protected



The Sterling II Emergency features the same construction and EOL protected ballast as the standard product. In addition it also provides three hours of battery backup for emergency operation in the case of a power outage.

Standard Specification

Features

Type of Protection	Ex nA (Non-sparking)
ATEX Classification	Group II Category 3 GD
Area Classification	Zone 2 and Zone 22 areas to EN 60079-10-1 and EN 60079-10-2 with installation to EN 60079-14
Certificate	EC Type Examination Certificate Sira 06ATEX4348X IEC Ex SIR 06.0108X
Coding	Ex II 3 GD Ex nA II T4 (refer to table for T rating and Ambient)
Enclosure	GRP with polycarbonate diffuser and stainless steel retaining clips
Reflector	White polyester painted zinc coated steel
Entry	2 x 20mm diameter holes, 1 at each end
Termination	4 core 4mm ² max. conductor with through wiring 16A rating
Installation	Two clearance holes for M8 fasteners located on rear of body, sealing washers provided
Control Gear	High Frequency ballast, electronic/inverter
Relamping	Access via front diffuser secured by quick release stainless steel clips
Burning Position	Universal
Ingress Protection	IP65 to EN 60529
Electrical Supply	220-254V 50/60Hz
Battery	Ni-Cd (6V)
Duration	3 hours
Emergency Output	18W 32% of one lamp 36W 14% of one lamp 58W 9% of one lamp

Polycarbonate diffuser

Through wiring as standard

High frequency control gear gives 50/60Hz operation, high power factor correction and regulation of lamp output.

Long life nickel cadmium batteries

Switchable mains supply for local operation

LED charge indicator

End of life (EOL) protected

International Approvals


ATEX

IECEx Compliant

Std. Cat No.	Wattage	Voltage	TClass	T°(Dust)	Ambient °C	Weight
ST2N/218/BI/EM	2x18W	220V-254V	T4	85	-20 to +40	4.6kg
ST2N/136/BI/EM	1x36W	220V-254V	T4	85	-20 to +40	5.3kg
ST2N/236/BI/EM	2x36W	220V-254V	T4	85	-20 to +40	5.6kg
ST2N/158/BI/EM	1x58W	220V-254V	T4	85	-20 to +40	5.7kg
ST2N/258/BI/EM	2x58W	220V-254V	T4	85	-20 to +40	6.1kg

Options – Suffix to Catalogue No.

/120	110-130V 50/60Hz AC - 36W & 58W only (Note: Upper ambient, limit of +30°C)	/NM	Non maintained version (Single lamp version only)
/MF	Mains fuse	/BMT	Battery management test

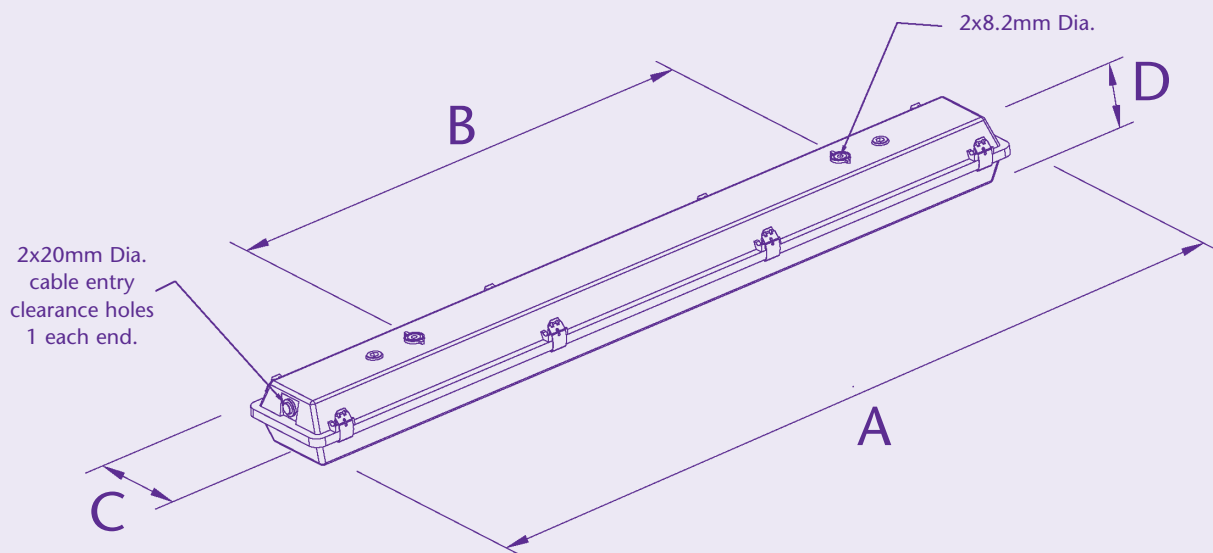

	2x18W	1x36W / 2x36W	1x58W / 2x58W
A	702	1312	1612
B	500	800	1100
C	172	102 / 172	102 / 172
D	106	106	106

Accessories Should be ordered separately

Catalogue Order Code

Pole mounting bracket assembly (38-42mm diameter poles)	SPOL4-100004
Pole mounting bracket assembly (48-52mm diameter poles)	SPOL4-100005
Pole mounting bracket assembly (58-62mm diameter poles)	SPOL4-100006
Hook type ceiling bracket assembly	S3004-100003
Ceiling bracket assembly	S3004-100001
Flush mounting wall bracket assembly	S3004-100004
18W wall mounting outreach bracket (use with SPOL4-100004)	NPRO4-0008
36W wall mounting outreach bracket (use with SPOL4-100004)	NPRO4-0012
58W wall mounting outreach bracket (use with SPOL4-100004)	NPRO4-0022

Product design and specifications are subject to change without notice, please check the Chalmit website for latest specifications.