




## COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

### Threaded/Set Screw Fittings: LB Body Only 2" Combo LB Type Body

C13.1

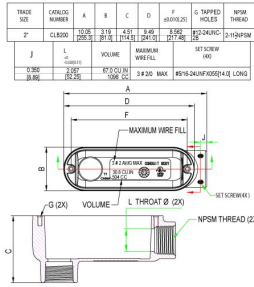

Catalog #: CLB200

#### APPLICATIONS

For use with threaded rigid/IMC conduit, or EMT, for pulling access or to split a run into multiple directions.  
N/A

#### PRODUCT FEATURES

- Durable die cast aluminum construction
- Premium powder coat finish
- Combination head screw

#### CULUS

Listed

#### NEMA

NEMA 3R Rated

#### NEC

2014 NEC Compliant

#### GENERAL PRODUCT INFORMATION

Trade Size: 2"  
 Description Table: 2" Combo LB Type Body

#### PACKAGING

Package Type: Carton  
 Std. Pkg.: -  
 Ship Carton Qty.: 5  
 Product UPC-A Labeled: Yes  
 Weight (Lbs. Per/C): 128  
 Ship Carton Length (in.): 16.73  
 Ship Carton Width (in.): 10.63  
 Ship Carton Height (in.): 5.71  
 Ctn Weight (Lbs.): 7.40  
 Pallet Qty: 300  
 UPC Number: 050169815236  
 I2of5: 50050169815231