


## Ground Clamp - Ball-Socket I-5 - 1"

By Chance Lineman Tools & Equipment  
Catalog # [C6002300](#)

For restricted-space applications and as a truck-grounding system, this compact design delivers a high-current rating usually associated with only larges. It applies to a wide range of switching equipment, including:Industrial metalclad gear,Substations — indoors and out,Distribution — overhead and underground.For trucks, a ball stud permanently mounts on each body. For three-phase livefront set, see page 3015. Two styles and two ball-stud lengths adapt to many applications. bodies and eyescrews are a bronze alloy.

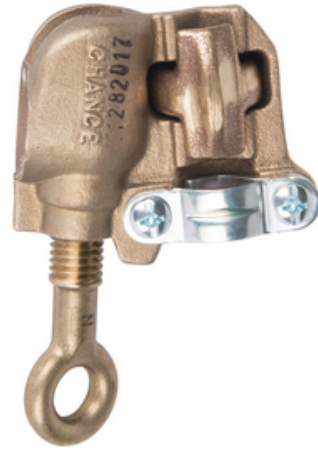

### Features

- Ball-stud ground clamp for 1" (25mm) ball-studs
- Pressure terminal for plain-plug ferrules
- Rated 43kA for 15 cycles and 30kA for 30 cycles
- Eye-screw for use with grip-all clamp-sticks

### General

Eye Screw/T-Handle	250 in-lb
Installation Torque (in-lb)	
Ferrule Installation Torque (in-lb)	250 in-lb
Handle Type	Eyescrew
Material	Bronze
Terminal Connection Type	Pressure
Thread Size	5/8-11 UNC
UPC	096359024422

### Dimensions

Weight	1.96 lb
--------	---------

### Electrical Ratings

Amperage Rating	43000 A
Current Rating	400 A
Fault Current - 15 Cycles	43000 A
Fault Current - 30 Cycles	30000 A
Grounding Wire Capacity Maximum	4/0 Cable w/ Plain Terminal
Grounding Wire Capacity Minimum	#2 Cable w/ Plain Terminal

### Certifications And Compliance

Fault Current - ASTM Grade	ASTM Grade 5
----------------------------	--------------

### Logistics

Carton Quantity	10
-----------------	----

### Product Assets

[Catalogs - Grounding Equipment](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
CLTE-C6002300-SPEC-EN | REV 6/2024