


Ground Clamp - All Angle I-B-5 2.88" Jaw Opening

By Chance Lineman Tools & Equipment
Catalog # [G422810SJ](#)

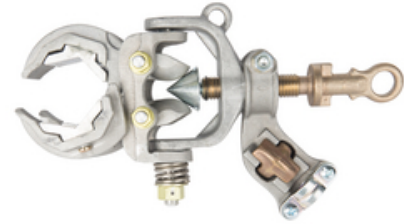

C-Type Grounding Clamp with eye screw, serrated jaw, ASTM Grade 5, 2.88" Jaw Opening

Features

- All-Angle Grounding Clamps
- Aluminum Bodies with Serrated Jaws
- For installation ease, jaws pivot 75° left or right.
- Tapped for 5/8-11 UNC threaded ferrule

General

Eye Screw/T-Handle	250 in-lb
Installation Torque (in-lb)	
Ferrule Installation Torque (in-lb)	250 in-lb
Handle Type	Eyescrew
Jaw Type	Serrated Jaws
Material	Aluminum
Terminal Connection Type	Pressure
UPC	096359038290

Dimensions

Dimensions	13.5 in x 6.23 in x 1.94 in
Height	1.94 in
Jaw Opening Size - Maximum	2.88 in
Jaw Opening Size - Minimum	.258 in
Length	13.5 in
Weight	3.185 lb
Width	6.23 in

Electrical Ratings

Current Rating	400 A
Fault Current - 15 Cycles	43000 A
Fault Current - 30 Cycles	30000 A
Grounding Wire Capacity Maximum	4/0 Cable w/ Plain Terminal
Grounding Wire Capacity Minimum	#2 Cable w/ Plain Terminal

Certifications And Compliance

Fault Current - ASTM Grade	ASTM Grade 5
----------------------------	--------------

Logistics

Pallet Quantity 200

Product Assets

[Catalogs - Grounding Equipment](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
CLTE-G422810SJ-SPEC-EN | REV 6/2024