


## Ground Clamp - All Angle I-B-5 1.196" Jaw Opening

By Chance Lineman Tools & Equipment  
Catalog # [G42291SJ](#)

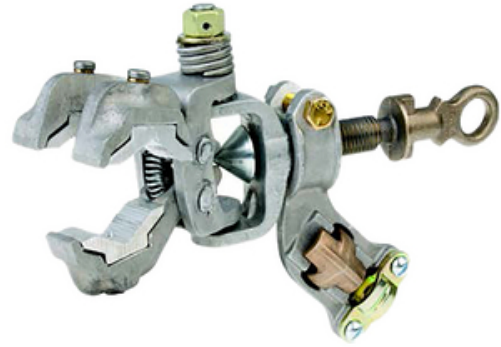

C-Type Grounding Clamp with eye screw, serrated jaw, ASTM Grade 5, 2.88" Jaw Opening

### Features

- All-Angle Grounding Clamps
- Aluminum Bodies with Serrated Jaws
- For installation ease, jaws pivot 75° left or right.
- Tapped for 5/8-11 UNC threaded ferrule

### General

Bolt Installation Torque  
(Recommended)

Eye Screw/T-Handle 250 in-lb

Installation Torque (in-lb)

Ferrule Installation Torque (in-lb) 250 in-lb

Handle Type Eyescrew

Jaw Type Serrated Jaws

Material Aluminum

Terminal Connection Type Pressure

UPC 096359038306

### Dimensions

Jaw Opening Size - Maximum 1.196 in

Jaw Opening Size - Minimum .258 in

Weight 2.205 lb

### Electrical Ratings

Current Rating 400 A

Fault Current - 15 Cycles 43000 A

Fault Current - 30 Cycles 30000 A

Grounding Wire Capacity  
Maximum 4/0 Cable w/ Plain Terminal

Grounding Wire Capacity  
Minimum #2 Cable w/ Plain Terminal

### Certifications And Compliance

Fault Current - ASTM Grade ASTM Grade 5

### Logistics

Carton Quantity 5

Pallet Quantity 150

### Product Assets

[Catalogs - Grounding Equipment](#)

[Sales Drawings - SA\\_G42291SJ](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
CLTE-G42291SJ-SPEC-EN | REV 6/2024