


BALL SOCKET CLAMP T-HANDLE 6H 35MM

By Chance Lineman Tools & Equipment
Catalog # [PSC6003713](#)

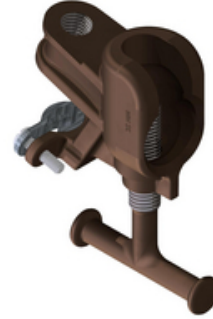

6H 35mm Ball Socket Clamps with T-Handle

Features

- 6H-Rated 35mm Ball Socket Clamps with bronze body
- Bronze T-Handle version with threaded ferrule holes - 5/8-11UNC
- Tested per ASTM F855-20 to Grade 6H (55kA, 148kA 1st cycle peak, X/R=30)
- Connect to PSC6003581 35mm Ball Stud
- PSS18102 4/OH Cable must be used to achieve 6H rating for the ground set
- Available with factory-assembled sets (recommended) or as an individual component

General

Eye Screw/T-Handle	300 in-lb
Installation Torque (in-lb)	
Ferrule Installation Torque (in-lb)	250 in-lb
Handle Type	T-Handle
Material	Bronze
Terminal Connection Type	5/8"-11 Thread
UPC	096359736127

Logistics

Pallet Quantity	720
-----------------	-----

Product Assets

[Catalogs - Grounding Equipment](#)

[Literature - 6H Ball Socket Clamps for 35MM Ball Stud](#)

[Sales Drawings - BALL STUD GROUND CLAMP, 35 mm](#)