

15kV Hotstick Jumper Set 15 ft (4.5 m) 1/0 Cable

By Chance Lineman Tools & Equipment
Catalog # [T6010284](#)

15kV, 15 ft of 1/0 cable, insulated jumper for hotstick applications, main line range of 0.162 in to 1.5 in

Features


- Meets ASTM F2321 Standard Specification
- Two C-type grounding clamps (C6001743) and two threaded copper ferrules
- Main Line Range: #6 solid copper (0.162”) through 1590kcmil ACSR (1.50”)
- 15kV EPR-insulated jumper cable
- Other clamps and cable combinations available upon request

General

Cable Length	15 ft
Cable Length Metric	4.5 m
Catalog Number	T6010284
EU RoHS Indicator	No
Style	Hotstick Applied
UPC	096359061878

Dimensions

Cable Length Metric	4.5 m
---------------------	-------

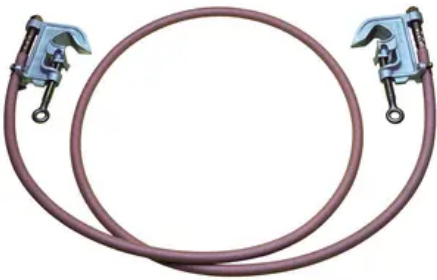

*Representative Image

Length	15 ft
Weight	15.6 lb
WeightMetric	7 kg

Electrical Ratings

Amperage Rating	260
Current Rating	260 A
Voltage - Maximum	15 kV
Voltage Rating	15 kV

Conductor Related

Conductor Diameter (Main) - Maximum	1.5 in
Conductor Diameter (Main) - Minimum	0.162 in
Conductor Size	1/0 AWG

Product Assets

[Specifications - T6010284](#)