


15kV Hotstick Jumper Set 12 ft (3.6 m) 2/0 Cable

By Chance Lineman Tools & Equipment

Catalog # [T6010285](#)

15kV, 12 ft of 2/0 cable, insulated jumper for hotstick applications, main line range of 0.162 in to 1.5 in

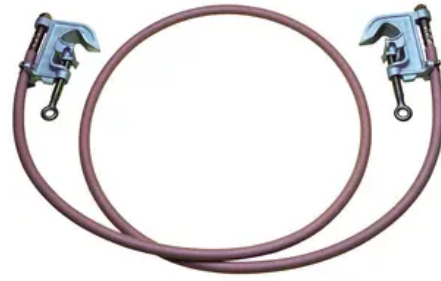

*Representative Image

Features

- Meets ASTM F2321 Standard Specification
- Two C-type grounding clamps (C6001743) and two threaded copper ferrules
- Main Line Range: #6 solid copper (0.162") through 1590kcmil ACSR (1.50")
- 15kV EPR-insulated jumper cable
- Other clamps and cable combinations available upon request

General

Cable Length	12 ft
Cable Length Metric	3.6 m
Catalog Number	T6010285
EU RoHS Indicator	No
Style	Hotstick Applied
UPC	096359061885

Dimensions

Cable Length Metric	3.6 m
Length	12 ft
Weight	14.7 lb
WeightMetric	6.6 kg

Electrical Ratings

Amperage Rating	300
Current Rating	300 A
Voltage - Maximum	15 kV
Voltage Rating	15 kV

Conductor Related

Conductor Diameter (Main) - Maximum	1.5 in
Conductor Diameter (Main) - Minimum	0.162 in
Conductor Size	2/0 AWG

Certifications And Compliance

Buy American Compliant	Contact Manufacturer
------------------------	----------------------

Logistics

Pallet Quantity	24
-----------------	----

Product Assets

[Catalogs - Jumpers & Load Pickup Tools](#)
[Specifications - T6010285](#)