


# 15kV Hotstick Jumper Set 15 ft (4.5 m) 4/0 Cable

By Chance Lineman Tools & Equipment  
Catalog # [T6010288](#)

15kV, 15 ft of 4/0 cable, insulated jumper for hotstick applications, main line range of 0.162 in to 1.5 in

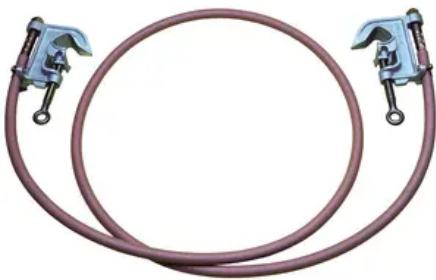

\*Representative Image

### Features

- Meets ASTM F2321 Standard Specification
- Two C-type grounding clamps (C6001743) and two threaded copper ferrules
- Main Line Range: #6 solid copper (0.162”) through 1590kcmil ACSR (1.50”)
- 15kV EPR-insulated jumper cable
- Other clamps and cable combinations available upon request

### General

Cable Length	15 ft
Cable Length Metric	4.5 m
Catalog Number	T6010288
EU RoHS Indicator	No
Style	Hotstick Applied
UPC	096359061915

### Dimensions

Cable Length Metric	4.5 m
Length	15 ft
Weight	23.5 lb

WeightMetric	10.6 kg
--------------	---------

### Electrical Ratings

Amperage Rating	400
Current Rating	400 A
Voltage - Maximum	15 kV
Voltage Rating	15 kV

### Conductor Related

Conductor Diameter (Main) - Maximum	1.5 in
Conductor Diameter (Main) - Minimum	0.162 in
Conductor Size	4/0 AWG

### Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
--------------------------	----------------------

### Product Assets

[Catalogs - Jumpers & Load Pickup Tools](#)  
[Specifications - T6010288](#)