


DATE: _____ LOCATION: _____
 TYPE: _____ PROJECT: _____
 CATALOG #: _____

tradeSELECT®

FEATURES

- 2'x2' and 2'x4' recessed sizes
- Choice of two color temperatures
- 80+ CRI
- 0–10V dimming, standard
- Universal voltage (120–277V)
- 3,300 to 5,000 nominal lumens
- Up to 118 lumens per watt
- Emergency battery backup available
- 5-Wire flex available

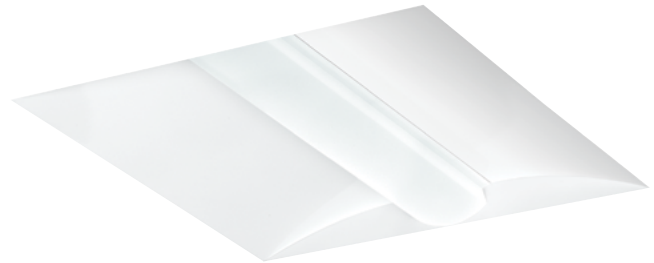

SPECIFICATIONS

OPTICS

- Frosted acrylic lens

INSTALLATION

- Fully assembled for quick installation

ELECTRICAL

- 54,000 hour LEDs at L70 for reduced maintenance

CERTIFICATIONS

- All luminaires are built to UL 1598 standards and bear appropriate CSA labels
- Damp location label standard
- Emergency-equipped fixtures labeled UL 924 unless specified
- IC rated

CERTIFICATIONS (CONTINUED)

- DLC® (DesignLights Consortium) Qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org

WARRANTY

- 5 year warranty
- See [HLI Standard Warranty](#) for additional information

ORDERING GUIDE


| Catalog Number | Description | Delivered Lumens | Watts | LPW | Qty on Pallet |
|-------------------------|--|------------------|-------|-----|---------------|
| CCL22-3335 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K | 3223 | 29 | 112 | 40 |
| CCL22-3335-C588 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, 5-Wire Flex ¹ | | | | |
| CCL22-3335-ELL14 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, 1400lm Battery Pack ¹ | | | | |
| CCL22-3340 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K | 3345 | 29 | 116 | 40 |
| CCL22-3340-C588 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, 5-Wire Flex ¹ | | | | |
| CCL22-3340-ELL14 | 2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, 1400lm Battery Pack ¹ | | | | |
| CCL24-5035 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K | 5001 | 44 | 114 | 20 |
| CCL24-5035-C588 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, 5-Wire Flex ¹ | | | | |
| CCL24-5035-ELL14 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, 1400lm Battery Pack ¹ | | | | |
| CCL24-5040 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K | 5191 | 44 | 118 | 20 |
| CCL24-5040-C588 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, 5-Wire Flex ¹ | | | | |
| CCL24-5040-ELL14 | 2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, 1400lm Battery Pack ¹ | | | | |

| Accessories (Order Separately) | |
|--------------------------------|--|
| FK22 | 2' x 2' Single Flange Kit (Shipped separately) |
| FK24 | 2' x 4' Single Flange Kit (Shipped separately) |

| KEY DATA | |
|-----------------------|------------|
| Lumen Range | 3223–5191 |
| Wattage Range | 29–44 |
| Efficacy Range (LPW) | 112–118 |
| Reported Life (Hours) | L70/54,000 |

Notes:
 1 Not stocked; ships in 5-10 days.

DIMENSIONS

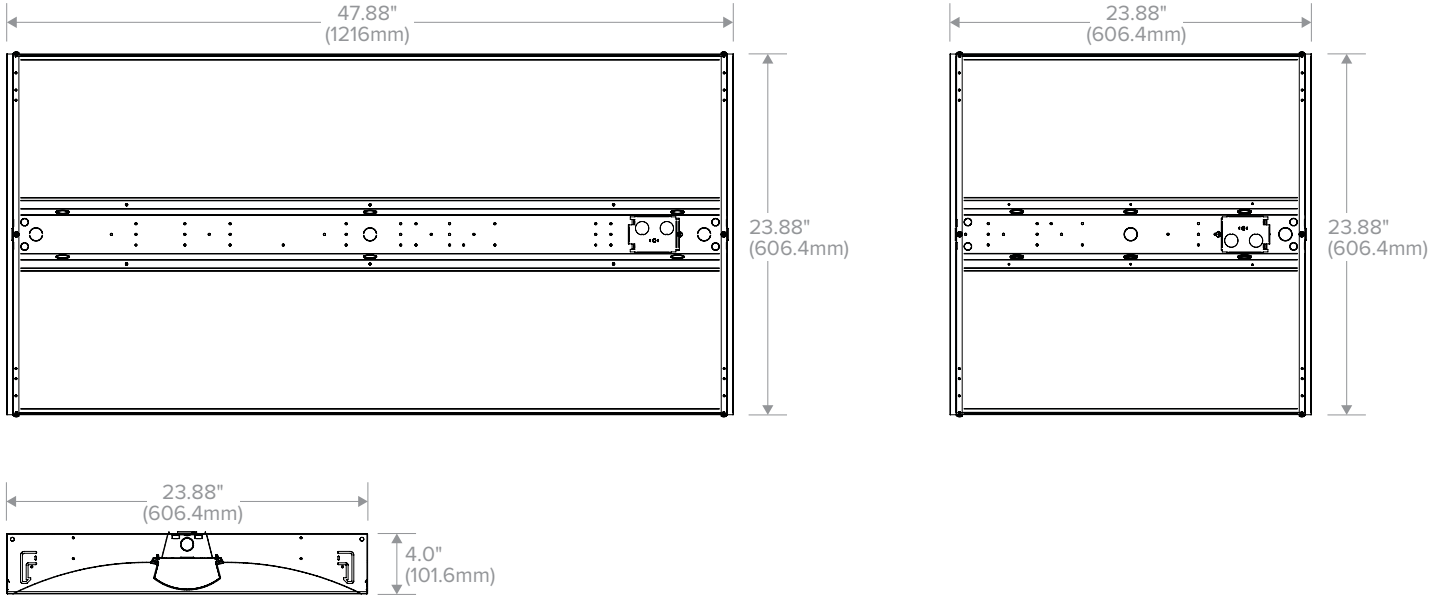

PHOTOMETRY

CCL22-3335


LUMINAIRE DATA

| | |
|-------------------|--|
| Test No. | 1700782 |
| Description | tradeSELECT® CCL Center Lens, Recessed Architectural 2x2 LED with linear prisms frosted acrylic lens |
| Delivered Lumens | 3223 |
| Watts | 28.90 |
| Efficacy | 112 |
| Mounting | Surface |
| Spacing Criterion | 0° = 1.20 90° = 1.29 |

ZONAL LUMEN SUMMARY

| Zone | Lumens | % Luminaire |
|-------|--------|-------------|
| 0-30 | 822 | 25.5 |
| 0-40 | 1341 | 41.6 |
| 0-60 | 2381 | 73.9 |
| 0-90 | 3223 | 100.0 |
| 0-180 | 3223 | 100.0 |

POLAR GRAPH

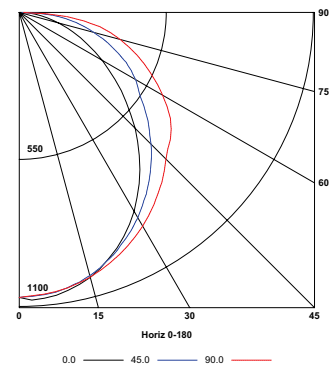

CCL24-5040

LUMINAIRE DATA

| | |
|-------------------|--|
| Test No. | 17774 |
| Description | tradeSELECT® CCL Center Lens, Recessed Architectural 2x4 LED with linear prisms frosted acrylic lens |
| Delivered Lumens | 5191 |
| Watts | 43.90 |
| Efficacy | 118 |
| Mounting | Surface |
| Spacing Criterion | 0° = 1.20 90° = 1.29 |

ZONAL LUMEN SUMMARY

| Zone | Lumens | % Luminaire |
|-------|--------|-------------|
| 0-30 | 1313 | 25.3 |
| 0-40 | 2142 | 41.3 |
| 0-60 | 3806 | 73.3 |
| 0-90 | 5191 | 100.0 |
| 0-180 | 5191 | 100.0 |

POLAR GRAPH

