

# CS Series

EXIT WITH DYNAMIC ACCESSIBILITY SIGN

tradeSELECT®

## FEATURES

- LED Life-cycle of more than 10 years
- Quick Installation
- Dual-Voltage 120/277VAC Input
- Includes long-life 2.4Vdc(Red) and 3.6Vdc(Green) Nickel Metal Hydride battery for UL recognized 90 minute emergency lighting
- Damp Location Listed 10°C to 40°C(50°F to 104°F)
- Includes push-to-test switch and AC-On indicator



## SPECIFICATIONS

### DESCRIPTION

- The CS Series is an Exit sign, also available with the Dynamic Symbol of Accessibility
- The CS Series is made of highly durable aluminum, with long-life LED's which provide bright and even EXIT illumination in AC only, or Emergency with battery to provide 90 minutes of emergency lighting in the event of power outage
- The CS offers quality and value with a durable and long-lasting aluminum housing and canopy
- The LED's are rated for a 10 year life-cycle. Available with the standard UL compliant

EXIT lettering at 6" tall, and for areas requiring the Dynamic Accessibility Symbol with 6" EXIT

- Available in red or green letters with matching red or green LED's
- Includes remove-able chevron knock-outs for directional indication
- The battery is easily accessible through a hinged front cover.
- The CS Exit offers universal single or double face, and can be ceiling, wall or end mounted

### APPLICATION

- The CS can be applied in commercial buildings, damp areas like basements, and complies with State of Connecticut Building Code requirements

### STANDARDS, CERTIFICATION, AND COMPLIANCE

- UL924 Damp Location Listed
- NFPA101 and NFPA70
- OSHA

### WARRANTY

- 2 year full unit warranty
- See [HLI Standard Warranty](#) for additional information

## ORDERING GUIDE

Catalog Number	Description
CSAUDR	Dynamic Accessibility Symbol, Red Letter, Universal Face, AC only
CSAUDG	Dynamic Accessibility Symbol, Green Letter, Universal Face, AC only
CSEUDR	Dynamic Accessibility Symbol, Red Letter, Universal Face, Emergency with Battery
CSEUDG	Dynamic Accessibility Symbol, Green Letter, Universal Face, Emergency with Battery
CSAUER	Exit, Red Letter, Universal Face, AC only
CSAUEG	Exit, Green Letter, Universal Face, AC only
CSEUER	Exit, Red Letter, Universal Face, Emergency with Battery
CSEUEG	Exit, Green Letter, Universal Face, Emergency, with Battery


# CS Series

EXIT WITH DYNAMIC ACCESSIBILITY SIGN


## ENERGY CONSUMPTION

Catalog Number	INPUT V.	INPUT CURRENT (A)	POWER
CSAUER	120V	0.027	3.1
	277V	0.012	3.2
CSAUEG	120V	0.044	5.1
	277V	0.02	5.3
CSEUER	120V	0.031	3.5
	277V	0.013	3.6
CSEUEG	120V	0.056	6.5
	277V	0.026	7.1
CSAUDR	120V	0.054	6.4
	277V	0.024	6.7
CSAUDG	120V	0.046	5.4
	277V	0.021	5.7
CSEUDR	120V	0.057	6.8
	277V	0.027	7.5
CSEUDG	120V	0.059	7.0
	277V	0.028	7.7

## DIMENSIONS

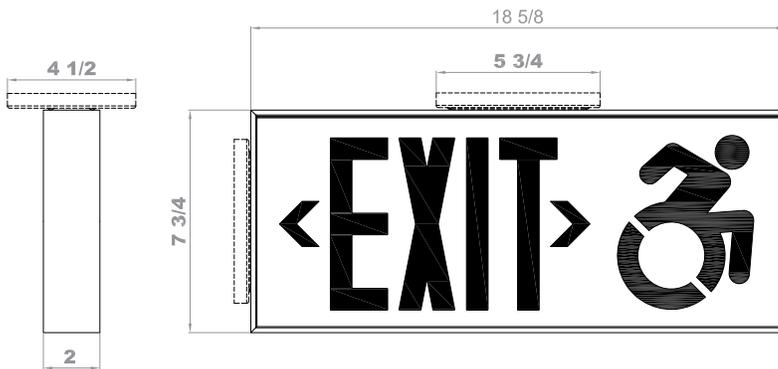

Single Carton Weight	6.1 lbs.
Master Carton Quantity	6 each

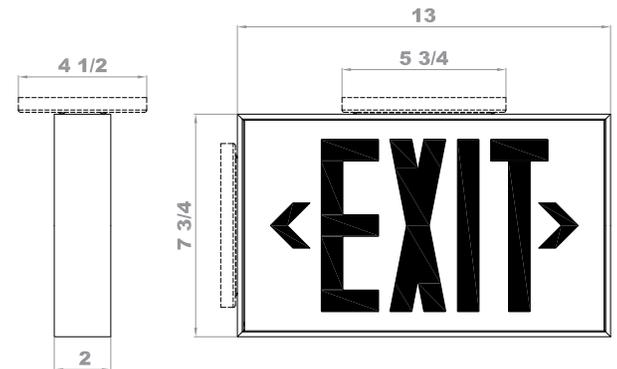

Single Carton Weight	4 lbs.
Master Carton Quantity	8 each