

FIBERHUBB™
Universal MPO Cassettes

Hubbell’s new Universal Wired MPO cassettes feature the latest in polarity management and low loss connectors all in one LGX footprint. Simplify ordering and installation by integrating the Hubbell Universal cassette into your fiber channel

When speed of deployment is paramount and labor is scarce, Hubbell can offer fully pre-terminated assemblies and cassettes that are plug-and-play ready. Our new universal wired cassettes make managing polarity as simple as 1-2-3!



Cassettes

Fiber	Ports	Configuration	Color	Catalog No.
OM4	12	MPO to LC Duplex	Aqua	OCLCUMM
OS2	12	MPO to LC Duplex	Blue	OCLCUSM
OM4	24	MPO to LC Duplex	Aqua	OCLCDUMM (1)
OS2	24	MPO to LC Duplex	Blue	OCLCDUSM (2)
OM4	24	MPO to LC Quad	Aqua	OCLCQUMM (3)
OS2	24	MPO to LC Quad	Blue	OCLCQUSM (4)

Add U to end of part number for Made in USA
*Ex. OCLCUMMU = OM4, 12F, LCD-MPO, UNI, AQ, USA




Polarity Configuration Chart

Product	Universal	Method A	Method B	Method C
Cassettes	Same	Same	Different	Same
Trunks	Ferrule Flipped*	Straight Through	Ferrule Flipped*	Pair Flipped
Patch Cords	Same	Different	Same	Same

*The connector ferrule containing the row of fibers is rolled on one side

Patch Cords

Fiber	Color	Configuration	Catalog No.
OM4	Aqua	LC Duplex to LC Duplex, 1 meter	FDLC1MM
OM4	Aqua	LC Duplex to LC Duplex, 2 meter	FDLC2MM
OM4	Aqua	LC Duplex to LC Duplex, 3 meter	FDLC3MM
OM4	Aqua	LC Duplex to LC Duplex, 5 meter	FDLC5MM
OS2	Yellow	LC Duplex to LC Duplex, 1 meter	FDLC1SM
OS2	Yellow	LC Duplex to LC Duplex, 2 meter	FDLC2SM
OS2	Yellow	LC Duplex to LC Duplex, 3 meter	FDLC3SM
OS2	Yellow	LC Duplex to LC Duplex, 5 meter	FDLC5SM

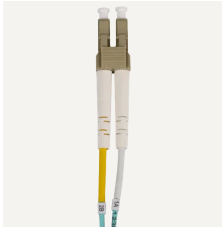

FDLC1MM


Trunk Assemblies

Fiber	Color	Configuration	Catalog No.
OM4	Aqua	12F, MPO to MPO, Type B, 10 Feet	FPCPMPOB50G4M10FN
OM4	Aqua	12F, MPO to MPO, Type B, 15 Feet	FPCPMPOB50G4M15FN
OM4	Aqua	12F, MPO to LC Duplex, 10 Feet	FHPMPLCM4L10FN
OM4	Aqua	12F, MPO to LC Duplex, 15 Feet	FHPMPLCM4L15FN
OS2	Yellow	12F, MPO to MPO, Type B, 10 Feet	FPCPMPOBS6L10FN
OS2	Yellow	12F, MPO to MPO, Type B, 15 Feet	FPCPMPOBS6L10FN
OS2	Yellow	12F, MPO to LC Duplex, 10 Feet	FHPMPLCS6L10FN
OS2	Yellow	12F, MPO to LC Duplex, 15 Feet	FHPMPLCS6L15FN




FPCPMPOB50G4M10FN

OCLCDUMM/SM

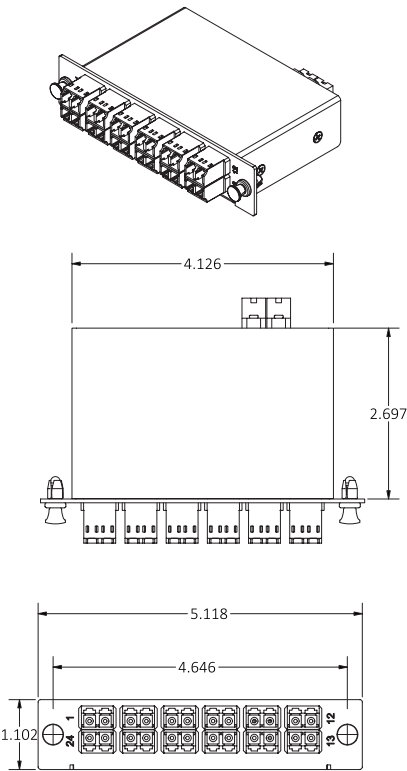

OCLCQUMM/SM

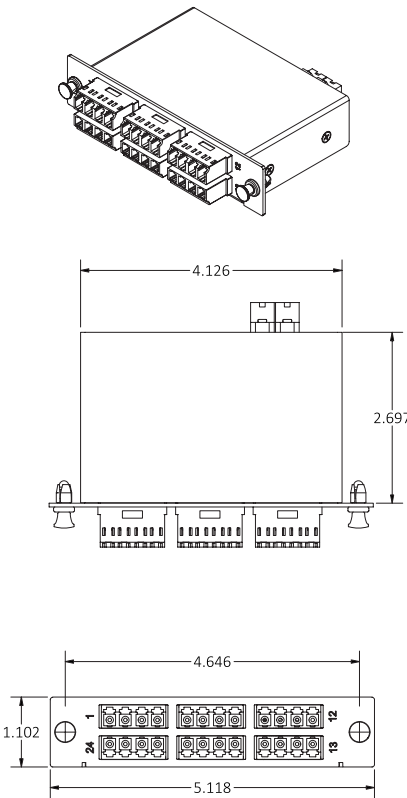

OCLCUMM/SM

