

# HUBBELL® Premise Wiring

## FIBERHUBB™ High Density FEHD Series

FiberHUBB™ FEHD Series features a new ultra compact design that is scalable for any fiber data center application.

Easily install 144 LC connections inside the 1U rack space with built in labeling features, slide out drawer, ample cable management features, and a robust construction that ensures protection. A true “plug-n-play” design, the FEHD Series has the flexibility to reconfigure, partition, or scale up to future migrations with interchangeable cassette modules.

### Features & Benefits


- Reinforced steel construction
- Easy-Slide out drawer
- Fully removable covers
- Built in cable management rings
- Accessory kit and label card included

### Specifications

- Height: 1.75”
- Width: 19”
- Overall Depth: 17.8”
- Depth to Mounting Flanges: 14.6”
- Weight: 21.6 lbs

### Applications

- Data Center fiber distribution and equipment interconnect
- SAN/LAN Interconnect facilities
- Rapid deployment high density interconnect
- Optical network partitioning and consolidation
- Retro-fit legacy networks for space consolidation

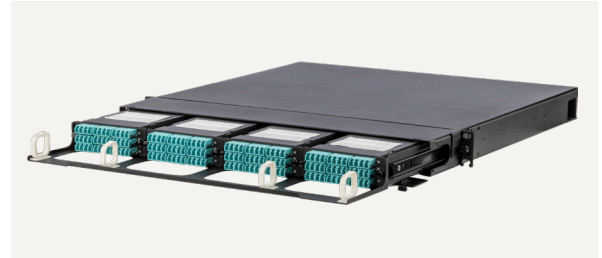

FEHD1U



FEHD2U



OCLCHDUMM





OCLCHDUSM



OCHDB



# Products

Enclosures	Catalog Number	Product
1U	FEHD1U	
2U	FEHD2U	


# Delivery

Fully assembled unit in a reinforced box with (4) #12-24 rack mounting screws, (4") Velcro, (10) zip ties, (4) adhesive backed managers, (4) cable hangers, ID chart


# Accessories

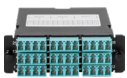Description	Catalog Number	Product
36-port LC to MPO cassette, OM4	OCLCHDUMM	
36-port LC to MPO cassette, OS2	OCLCHDUSM	
Blank Module	OCHDB	
24-Fiber, MPO-LC Trunk Assembly, Type A, OM4 (customizable)	FPC-LTP24M4AQ-MPO-LC-A-NPE	
48-Fiber, MPO-MPO Trunk Assembly, Type B, OS2 (customizable)	FPC-LTP48SMYW-MPO-MPO-B-NPE	
OM4 Duplex Patch Cord, 1 meter	FDLC1MM	
OS2 Duplex Patch Cord, 2 meter	FDLC2SM	

FEHD1U

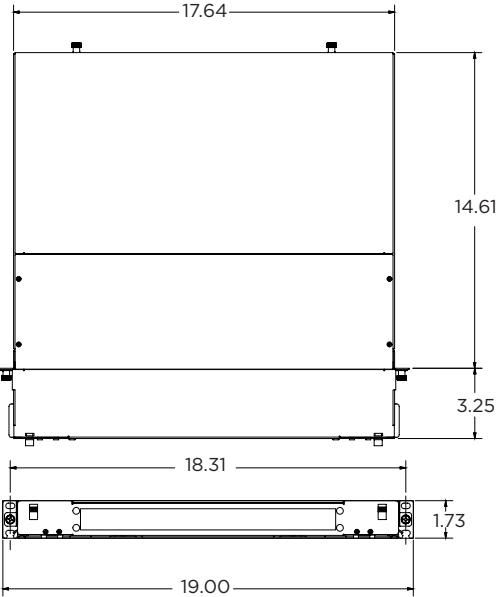

FEHD2U

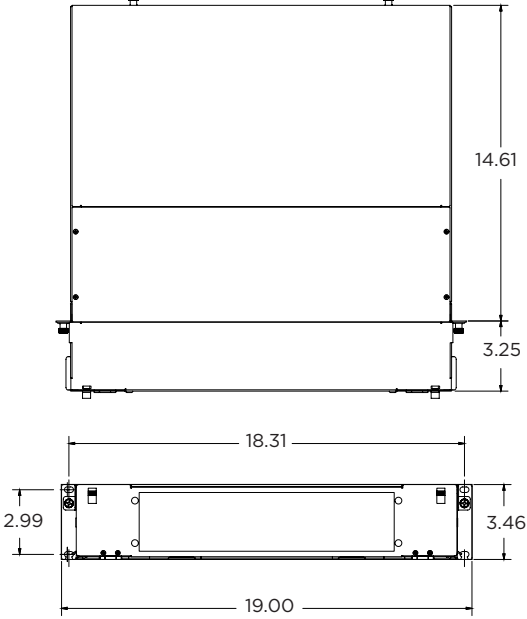

# Full Rack Solution

