



Catalog # 509

3 IN. X 2 IN. SWITCH BOXES - 1-1/2 TO 2-1/2 IN. DEEP WITH CONDUIT KO'S

2-1/2 IN. DEEP SWITCH BOXES - GANGABLE WITH CONDUIT KO'S OLD WORK, PLASTER EARS

APPLICATIONS

RACO® Switch boxes are used to house wiring devices such as switches and outlets

FEATURES

- Gangable switch boxes offer the option of constructing a box to hold two or more devices
- Plaster ears allow a box to be used in "old work" applications

CERTIFICATIONS



COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2-hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

WIRING SYSTEM: CONDUIT

CONFIGURATION


END KNOCKOUTS: (2) 1/2 IN.
 BRACKET TYPE: NO BRACKET
 BOTTOM KNOCKOUT(S): (2) 1/2 IN.

DRAWING DIMENSIONS

DIMENSION A: 2-1/2 IN.

PRODUCT MEASUREMENTS

DEPTH: (2) 1/2 IN.
 CUBIC INCHES (CM³): 12.5 (204.8)
 WT. EA. (LBS.): 0.612
 PRODUCT LENGTH (IN.): 2.50
 PRODUCT WIDTH (IN.): 4.22
 PRODUCT HEIGHT (IN.): 2.63

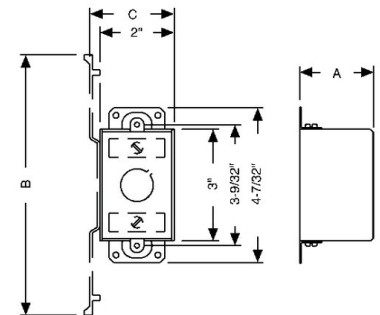

PACKAGING

MINIMUM PACK QTY.: 20
 STANDARD PACKAGING: 20
 PRODUCT UPC-A LABELED: YES
 WEIGHT (LBS. PER/C): 61.20
 SHIP CARTON LENGTH (IN.): 12.94
 SHIP CARTON WIDTH (IN.): 5.75
 SHIP CARTON HEIGHT (IN.): 8.13
 CTN WEIGHT (LBS.): 12.23
 PALLET QTY: 2520
 UPC NUMBER: 050169005095
 I2OF5: 50050169005090

