



Catalog # 8650

SINGLE DEVICE HANDY BOXES & EXTENSION RINGS

4 IN. X 2 IN. HANDY BOXES, 1-1/2 IN. DEEP - WELDED WITH CONDUIT KO'S

APPLICATIONS

RACO® Handy boxes, also called utility boxes, are used for convenience outlets, switch boxes or small junction boxes

CERTIFICATIONS



COMPLIANCES

All RACO® single gang, two gang, 4 in. square, and single gang gangable UL listed steel boxes are acceptable for use in 2hour fire rated walls. For additional information, consult UL "Fire Resistance Directory" or the UL website at www.ul.com

FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

WIRING SYSTEM: CONDUIT

CONFIGURATION


END KNOCKOUTS: (2) 1/2 IN.
DRAWN OR WELDED: WELDED
RAISED GROUND: NO
SIDE KNOCKOUT(S): (6) 1/2 IN.
BOTTOM KNOCKOUTS(S): (3) 1/2 IN.

DRAWING DIMENSIONS

DIMENSION A: 2-1/2 IN.

PRODUCT MEASUREMENTS

DEPTH: 1-1/2 IN.
CUBIC INCHES (CM³): 11.5 (188.5)
WT. EA. (LBS.): 0.478
PRODUCT LENGTH (IN.): 1.56
PRODUCT WIDTH (IN.): 4.00
PRODUCT HEIGHT (IN.): 2.13

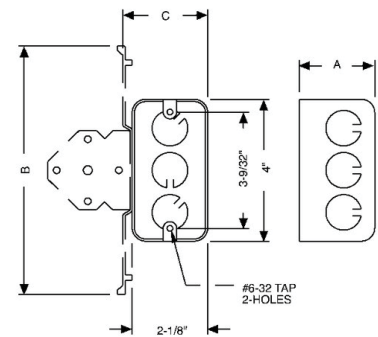

PACKAGING

MINIMUM PACK QTY.: 25
STANDARD PACKAGING: 25
PRODUCT UPC-A LABELED: YES
WEIGHT (LBS. PER/C): 47.80
SHIP CARTON LENGTH (IN.): 11.50
SHIP CARTON WIDTH (IN.): 5.25
SHIP CARTON HEIGHT (IN.): 9.25
CTN WEIGHT (LBS.): 11.95
PALLET QTY: 3600
UPC NUMBER: 050169006504
I2OF5: 40050169006502

