



Catalog # 8670

SINGLE DEVICE HANDY BOXES & COVERS

4 IN. X 2 IN. HANDY BOXES, 2-1/8 IN. DEEP - WELDED WITH CONDUIT KO'S

APPLICATIONS

RACO® Handy boxes, also called utility boxes, are used for convenience outlets, switch boxes or small junction boxes

CERTIFICATIONS



FIRE RESISTANCE

Acceptable for use in 2-hour rated walls

GENERAL PRODUCT INFORMATION

WIRING SYSTEM: CONDUIT

CONFIGURATION


END KNOCKOUTS: (2) 1/2 IN.
 BRACKET TYPE: NO BRACKET
 DRAWN OR WELDED: WELDED
 RAISED GROUND: NO
 SIDE KNOCKOUT(S): (6) 1/2 IN.
 BOTTOM KNOCKOUTS(S): (3) 1/2 IN.

DRAWING DIMENSIONS

DIMENSION A: 2-1/8 IN.

PRODUCT MEASUREMENTS

DEPTH: 2-1/8 IN.
 CUBIC INCHES (CM³): 16.5 (270.4)
 WT. EA. (LBS.): 0.609
 PRODUCT LENGTH (IN.): 2.19
 PRODUCT WIDTH (IN.): 4.00
 PRODUCT HEIGHT (IN.): 2.13

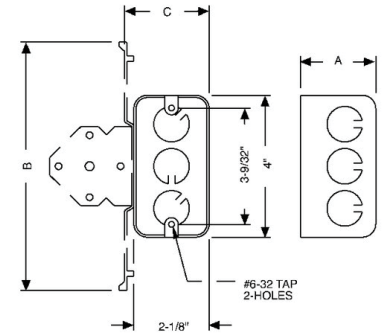

PACKAGING

MINIMUM PACK QTY.:	25
STANDARD PACKAGING:	25
PRODUCT UPC-A LABELED:	YES
WEIGHT (LBS. PER/C):	60.90
SHIP CARTON LENGTH (IN.):	13.00
SHIP CARTON WIDTH (IN.):	7.50
SHIP CARTON HEIGHT (IN.):	7.25
CTN WEIGHT (LBS.):	15.23
PALLET QTY:	2700
UPC NUMBER:	050169006702
I2OF5:	40050169006700

