


## Formed Wire Deadend for Alumoweld® Strand 6M

By FARGO  
Catalog # [AWDE4110](#)

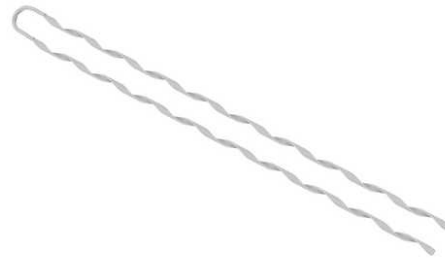

Formed Wire Deadend for 6M Alumoweld® Guy Strand

\*Representative Image

### Features

- For Alumoweld® Guy Strand
- Alumoweld® wire construction
- 6,000lb (26.7kN) maximum RBS

### Application

Deadend for Alumoweld® Guy Strand

### General

Color Code	Yellow
Material	Aluminum Clad Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359395560

### Dimensions

Length	22 in
Nominal Guy Wire Size	6M, 3#9 Alumoweld®
Weight	0.400 lb

### Conductor Related

Conductor Diameter - Maximum	0.259 in
Conductor Diameter - Minimum	0.231 in
Conductor Diameter Range	0.231 - 0.259
Conductor Type	Alumoweld®
Guy Wire Type	Alumoweld®

### Logistics

Carton Quantity	50
Pallet Quantity	1400

### Product Assets

[Catalogs - Communications Catalog \(CA12042E\)](#)  
[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Sales Drawings - AWDE, Formed wire deadends](#)

### Related Products

[AWDE4120 - Formed Wire Deadend for Alumoweld® Strand 14M](#)  
[AWDE4108 - Formed Wire Deadend for Alumoweld® Strand 4M](#)