


## Formed Wire Deadend for Alumoweld® Strand 20M

By FARGO  
Catalog # [AWDE4126](#)

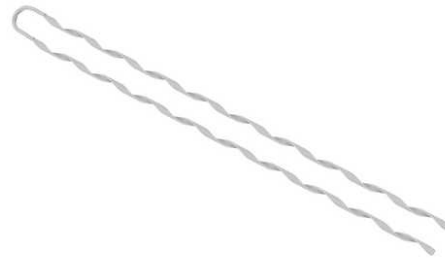

Formed Wire Deadend for 20M Alumoweld® Guy Strand

\*Representative Image

### Features

- For Alumoweld® Guy Strand
- Alumoweld® wire construction
- 20,000lb (89.0kN) maximum RBS

### Application

Deadend for Alumoweld® Guy Strand

### General

Color Code	Yellow
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Clad Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359395591

### Dimensions

Length	36 in
Nominal Guy Wire Size	20M Alumoweld®
Weight	2.200 lb

### Conductor Related

Conductor Diameter - Maximum	0.474 in
Conductor Diameter - Minimum	0.431 in
Conductor Diameter Range	0.431 - 0.474
Conductor Type	Alumoweld®
Guy Wire Type	Alumoweld®

### Logistics

Carton Quantity	50
Pallet Quantity	490

### Product Assets

[Catalogs - Communications Catalog \(CA12042E\)](#)  
[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Sales Drawings - AWDE, Formed wire deadends](#)

### Related Products

[AWDE4122 - Formed Wire Deadend for Alumoweld® Strand 16M](#)  
[AWDE4128 - Formed Wire Deadend for Alumoweld® Strand 7#6](#)