


## Formed Wire Deadend for Alumoweld® Strand 7#6

By FARGO  
Catalog # [AWDE4128](#)

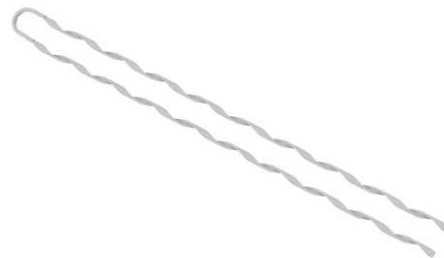

Formed Wire Deadend for 7#6 Alumoweld® Guy Strand

\*Representative Image

### Features

- For Alumoweld® Guy Strand
- Alumoweld® wire construction
- 22,730lb (101.1kN) maximum RBS

### Application

Deadend for Alumoweld® Guy Strand

### General

Color Code	Blue
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Clad Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359395607

### Dimensions

Length	40 in
Nominal Guy Wire Size	7#6 Alumoweld®
Weight	2.300 lb

### Conductor Related

Conductor Diameter - Maximum	0.515 in
Conductor Diameter - Minimum	0.475 in
Conductor Diameter Range	0.475 - 0.515
Conductor Type	Alumoweld®
Guy Wire Type	Alumoweld®

### Logistics

Carton Quantity	50
Pallet Quantity	280

### Product Assets

[Catalogs - Communications Catalog \(CA12042E\)](#)  
[Catalogs - Distribution Connectors \(CA05127E\)](#)  
[Literature - Ropes Course Industry Letter \(April 2021\)](#)  
[Sales Drawings - AWDE, Formed wire deadends](#)

### Related Products

[AWDE4130 - Formed Wire Deadend for Alumoweld® Strand 25M](#)  
[AWDE4126 - Formed Wire Deadend for Alumoweld® Strand 20M](#)