


Formed Wire Deadend for Alumoweld® Strand 25M

By FARGO
Catalog # [AWDE4130](#)

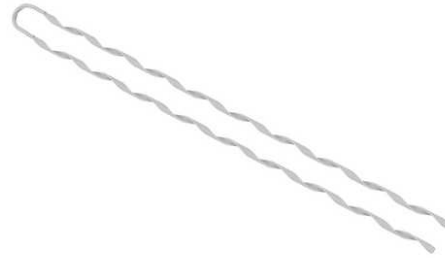

Formed Wire Deadend for 25M Alumoweld® Guy Strand

*Representative Image

Features

- For Alumoweld® Guy Strand
- Alumoweld® wire construction
- 25,000lb (111.2kN) maximum RBS

Application

Deadend for Alumoweld® Guy Strand

General

Color Code	Red
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Clad Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359395614

Dimensions

Length	43 in
Nominal Guy Wire Size	25M Alumoweld®
Weight	3.100 lb

Conductor Related

Conductor Diameter - Maximum	0.535 in
Conductor Diameter - Minimum	0.516 in
Conductor Diameter Range	0.516 - 0.535
Conductor Type	Alumoweld®
Guy Wire Type	Alumoweld®

Logistics

Carton Quantity	50
Pallet Quantity	300

Product Assets

[Catalogs - Communications Catalog \(CA12042E\)](#)
[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - AWDE, Formed wire deadends](#)

Related Products

[AWDE4131 - Formed Wire Deadend for Alumoweld® Strand 7#5](#)
[AWDE4128 - Formed Wire Deadend for Alumoweld® Strand 7#6](#)