


Formed Wire Deadend for Alumoweld® Strand 7#5

By FARGO
Catalog # [AWDE4131](#)

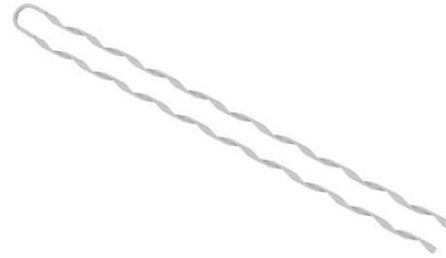

Formed Wire Deadend for 7#5 Alumoweld® Guy Strand

*Representative Image

Features

- For Alumoweld® Guy Strand
- Alumoweld® wire construction
- 27,030lb (120.2kN) maximum RBS

Application

Deadend for Alumoweld® Guy Strand

General

Color Code	Yellow
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum Clad Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359471622

Dimensions

Dimensions	45.000 in x 0.733 in x 3.841 in
Height	3.841 in
Length	45.000 in
Nominal Guy Wire Size	7#5 Alumoweld®
Weight	3.200 lb
Width	0.733 in

Conductor Related

Conductor Diameter - Maximum	0.57 in
Conductor Diameter - Minimum	0.536 in
Conductor Diameter Range	0.536 - 0.57
Conductor Type	Alumoweld®
Guy Wire Type	Alumoweld®

Logistics

Carton Quantity	50
Pallet Quantity	300

Product Assets

[Catalogs - Communications Catalog \(CA12042E\)](#)
[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Sales Drawings - AWDE, Formed wire deadends](#)

Related Products

[AWDE4128 - Formed Wire Deadend for Alumoweld® Strand 7#6](#)
[AWDE4130 - Formed Wire Deadend for Alumoweld® Strand 25M](#)