


Formed Wire Deadend for Bezinal® Guy Strand 7/32"

By FARGO
Catalog # [BDE9103](#)

Formed Wire Deadend for 7/32" Bezinal® Guy Strand

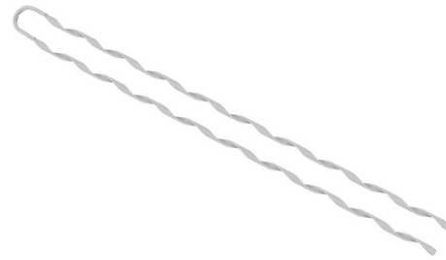

*Representative Image

Features

- For Bezinal® Guy Strand
- Bezinal® (B-coat) wire construction
- 5,400lb (24.0kN) maximum RBS

Application

Deadend for Bezinal® Guy Strand

General

Color Code	Green
Material	Zinc-Aluminum Coated Steel
Product Category	Guy Wire
Type	Formed Wire
UPC	096359582199

Dimensions

Length	24 in
Nominal Guy Wire Size	7/32" Bezinal®
Weight	0.380 lb

Conductor Related

Conductor Diameter - Maximum	0.230 in
Conductor Diameter - Minimum	0.204 in
Conductor Diameter Range	0.204 - 0.230
Conductor Type	Bezinal® and other common Zinc-Aluminum coated strand
Guy Wire Type	Bezinal® and other common Zinc-Aluminum coated strand

Logistics

Carton Quantity	50
-----------------	----

Product Assets

[Catalogs - Distribution Connectors \(CA05127E\)](#)
[Literature - Ropes Course Industry Letter \(April 2021\)](#)
[Literature - SF05122E_0319_Formed Wire Deadend](#)
[Sales Drawings - BDE Formed Wire Deadend](#)

Related Products

[BDE9104 - Formed Wire Deadend for Bezinal® Guy Strand 1/4"](#)
[BDE9102 - Formed Wire Deadend for Bezinal® Guy Strand 3/16"](#)